


nVent CADDY Rod Lock Spring Steel Rod Hanger with Nail Gun Bracket



CERTIFICATIONS

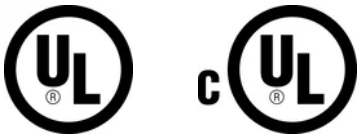

CARACTERISTICI

Suspends threaded rod without the need for additional hardware

Complete with concrete nail gun insert bracket

Clips onto nozzle of gas or battery-actuated nail guns allowing for hands-off installation at structure or from the floor using a pole

Longer leg angle bracket for tool clearance

Quickly and easily attaches to concrete, steel or composite metal decking

Easy "push-to-install" design allows installers to simply push the threaded rod through the mounting hole, instantly holding it in position

Prefabricated assemblies easily lift and lock into place, helping to save time and money

Works with slightly damaged threads and minor burrs on threaded rod ends

Design includes a release mechanism that works with pliers

SPECIFICAȚII

Table 1/2

Număr de catalog	Article Number	Material	Finish	Rod Size (RS)	Height (H)	Width (W)
4QTIGBSF	170896	Spring Oțel, Oțel, Nylon	nVent CADDY Armour, Electro galvaniz ed	6	48.7 mm	66.8 mm

Table 2/2


Număr de catalog	Article Number	A	B	Static Load
4QTIGBSF	170896	46.4 mm	36 mm	330N

DETALII SUPLIMENTARE DESPRE PRODUS

Static Load represents the static load of the nail gun insert assembly. Please consult with the nail manufacturer to evaluate the static load of the nail and type of concrete used for the installation. Maximum load is the lesser of the static load from the nail manufacturer or the published load for the assembly.

Nail gun insert is compatible with BeA® CN60-688ES, Hilti® BX 3, GX 3, DEWALT® Trak-It C3, SPIT® PULSA 40E, 800E, 700, 1000 or equivalent nailers.

DIAGRAMS

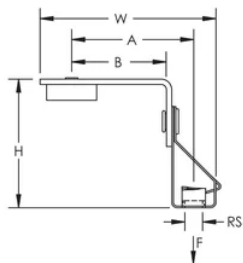

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răni corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

