

nVent CADDY Self-Cutting Cable Tie



The nVent CADDY Self-Cutting Cable Tie is a versatile, tool-free datacom solution for bundling large amounts of cables. This simple, yet innovative product features a built-in cutting blade to ensure a secure fastening and a safe, clean tie-off finish. Made from durable 6/6 nylon, the Self-Cutting Cable Tie boasts a robust 50lb/ 22Kg of tensile strength.

CERTIFICATIONS



CARACTERISTICI

Eliminates sharp edges and protects exposed skin from cuts during installation

Lock and twist to cut, no cutting tools required

Different colors including a black UV-protected version to meet specific needs

RoHS (Restriction of Hazardous Substances Directive) compliant

Halogen free

cULus Listed to UL 62275/CSA C22.2 No. 62275, UL Certified to IEC 62275

SPECIFICAȚII

Complies With: IEC® 60695-2-11 (Glow Wire Test 960 °C)

Table 1/2



Număr de catalog	Article Number	Material	Color	Length (L)	Width (W)	Installation Temperature
CADTIESC8CNA P	601019	Nylon, Stainless Steel 301 (EN 1.4310)	Natural	203.2mm	4.32 mm	0 °C Min
CADTIESC11CN AP	601001	Nylon, Stainless Steel 301 (EN 1.4310)	Natural	279.4mm	4.32 mm	0 °C Min

Număr de catalog	Article Number	Material	Color	Length (L)	Width (W)	Installation Temperature
CADTIESC14CBAP	601009	Nylon, Stainless Steel 301 (EN 1.4310)	Black	355.6mm	4.32 mm	0 °C Min
CADTIESC14CNAP	601010	Nylon, Stainless Steel 301 (EN 1.4310)	Natural	355.6mm	4.32 mm	0 °C Min
CADTIESC11CBAP	601000	Nylon, Stainless Steel 301 (EN 1.4310)	Black	279.4mm	4.32 mm	0 °C Min
CADTIESC8CBAP	601018	Nylon, Stainless Steel 301 (EN 1.4310)	Black	203.2mm	4.32 mm	0 °C Min

Table 2/2

Număr de catalog	Article Number	Operating Temperature
CADTIESC8CNAP	601019	-20 to 85 °C
CADTIESC11CNAP	601001	-20 to 85 °C
CADTIESC14CBAP	601009	-20 to 85 °C
CADTIESC14CNAP	601010	-20 to 85 °C
CADTIESC11CBAP	601000	-20 to 85 °C
CADTIESC8CBAP	601018	-20 to 85 °C

 DIAGRAMS

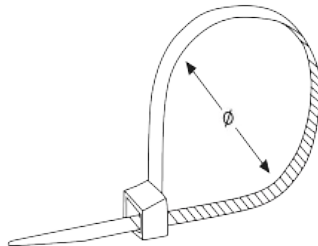

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

