

nVent CADDY Speed Link Light Pack with Nail Gun Bracket



The nVent CADDY Speed Link Light Pack with Nail Gun Bracket includes a precut length (1m and 2m) of 1mm wire rope riveted to an angle bracket designed for direct fastening together with an ultra-low-profile locking device. Contractors can quickly and safely install it to the concrete ceiling using a wide range of nail guns to support and secure lighting and signage.

CARACTERISTICI

Complete system includes wire, locking device and concrete nail gun insert bracket

Clips onto nozzle of gas or battery-actuated nail guns allowing for hands-off installation at structure or from the floor using a pole

Longer leg angle bracket for tool clearance

Quickly and easily attaches to concrete, steel or composite metal decking

SPECIFICAȚII

Static Load Safety Factor: 5:1

Finish: Electrogalvanized

Table 1/2

Număr de catalog	Article Number	Material	Wire Rope Diameter	Wire Rope Length	A	B
CLP1L1GBSF	196091	Oțel, Brass	1 mm	1m	38 mm	25.5 mm
CLP1L2GBSF	196092	Oțel, Brass	1 mm	2m	38 mm	25.5 mm

Table 2/2

Număr de catalog	Article Number	Static Load
------------------	----------------	-------------

CLP1L1GBSF	196091	100N
CLP1L2GBSF	196092	100N

Thickness (T): 6.5 mm

Width (W): 12.5 mm

Height (H): 21 mm


Angle (a): 60 °

DETALII SUPLIMENTARE DESPRE PRODUS

Static Load represents the static load of the nail gun insert assembly. Please consult with the nail manufacturer to evaluate the static load of the nail and type of concrete used for the installation. Maximum load is the lesser of the static load from the nail manufacturer or the published load for the assembly.

Nail gun insert is compatible with BeA® CN60-688ES, Hilti® BX 3, GX 3, DEWALT® Trak-It C3, SPIT® PULSA 40E, 800E, 700, 1000 or equivalent nailers.

DIAGRAMS

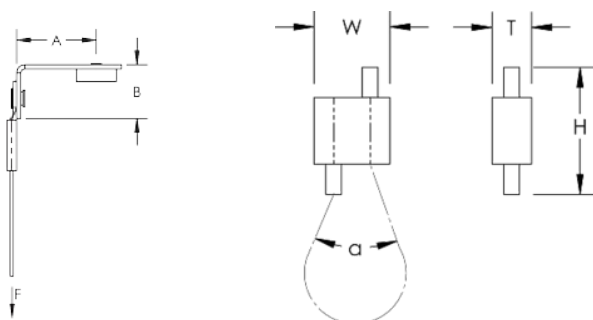

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

