

nVent CADDY Speed Link SLK with Threaded Stud End



CERTIFICATIONS



CARACTERISTICI

Complete system includes wire, locking device and pre-assembled threaded stud end fitting

Attaches to structures with threaded anchors or devices with threaded hole

Connects directly to threaded devices in trapeze assemblies, light fixtures, HVAC assemblies or signage

SPECIFICAȚII

Static Load Safety Factor:	5:1
Finish:	Electrogalvanized
Complies With:	SMACNA HVAC-DCS

Table 1/2

Număr de catalog	Article Number	Material	Wire Rope Diameter	Wire Rope Length	Rod Size (RS)	Screw Length (L)
SLK15L1SEM6	196564	Steel, Polypropylene, Zinc Alloy	1.5 mm	1m	6	25mm


Număr de catalog	Article Number	Material	Wire Rope Diameter	Wire Rope Length	Rod Size (RS)	Screw Length (L)
SLK15L1SEM8	196565	Steel, Polypropylene, Zinc Alloy	1.5 mm	1m	8	45mm
SLK15L2SEM6	196566	Steel, Polypropylene, Zinc Alloy	1.5 mm	2m	6	25mm
SLK15L2SEM8	196567	Steel, Polypropylene, Zinc Alloy	1.5 mm	2m	8	45mm
SLK15L3SEM6	196568	Steel, Polypropylene, Zinc Alloy	1.5 mm	3m	6	25mm
SLK15L3SEM8	196570	Steel, Polypropylene, Zinc Alloy	1.5 mm	3m	8	45mm
SLK2L2SEM8	196559	Steel, Polypropylene, Zinc Alloy	2 mm	2m	8	45mm
SLK2L3SEM8	196561	Steel, Polypropylene, Zinc Alloy	2 mm	3m	8	45mm
SLK2L5SEM6	196562	Steel, Polypropylene, Zinc Alloy	2 mm	5m	6	25mm
SLK2L5SEM8	196563	Steel, Polypropylene, Zinc Alloy	2 mm	5m	8	45mm

Table 2/2

Număr de catalog	Article Number	Height (H)	Width (W)	Thickness (T)	Angle (a)	Static Load
SLK15L1SEM6	196564	55 mm	19 mm	12.5 mm	90 ° Max	195N
SLK15L1SEM8	196565	55 mm	19 mm	12.5 mm	90 ° Max	195N
SLK15L2SEM6	196566	55 mm	19 mm	12.5 mm	90 ° Max	195N
SLK15L2SEM8	196567	55 mm	19 mm	12.5 mm	90 ° Max	195N
SLK15L3SEM6	196568	55 mm	19 mm	12.5 mm	90 ° Max	195N

Număr de catalog	Article Number	Height (H)	Width (W)	Thickness (T)	Angle (a)	Static Load
SLK15L3SEM8	196570	55 mm	19 mm	12.5 mm	90 ° Max	195N
SLK2L2SEM8	196559	55 mm	19 mm	12.5 mm	90 ° Max	440N
SLK2L3SEM8	196561	55 mm	19 mm	12.5 mm	90 ° Max	440N
SLK2L5SEM6	196562	55 mm	19 mm	12.5 mm	90 ° Max	440N
SLK2L5SEM8	196563	55 mm	19 mm	12.5 mm	90 ° Max	440N

DIAGRAMS

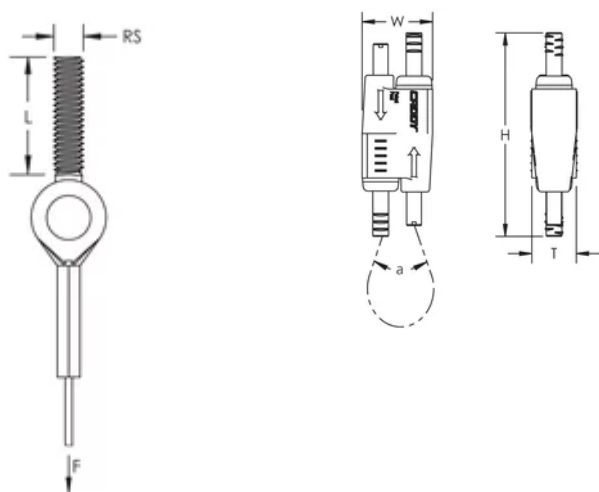

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răni corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

