

nVent CADDY Speed Link SLK with Y-Hook



CERTIFICATIONS



CARACTERISTICI

Complete system includes wire, locking device and two pre-assembled hook end fittings

Fastens to the building structure and hooks to hanging services and tray

Spring latch helps provide secure connection

Convenient design allows one hook to be temporarily detached for maintenance or to add cables to the tray

Single drop with double hook provides increased stability to the system

Also available in a single-hook end fitting configuration

SPECIFICAȚII

Wire Rope Diameter:	2 mm
Static Load Safety Factor:	5:1
Finish:	Electrogalvanized
Complies With:	SMACNA HVAC-DCS

Table 1/2

Număr de catalog	Article Number	Material	Wire Rope Length	Wire Rope "Y" Length (YL)	A	B
------------------	----------------	----------	------------------	---------------------------	---	---

SLK2YH500L3	196550	Steel, Zinc Alloy, Polypropylene	3m	0.5m	58.4 mm	22.9 mm
SLK2YH500L7	196551	Steel, Zinc Alloy, Polypropylene	7m	0.5m	58.4 mm	22.9 mm
SLK2YH500L2	196549	Steel, Zinc Alloy, Polypropylene	2m	0.5m	58.4 mm	22.9 mm

Table 2/2

Număr de catalog	Article Number	C	Static Load
SLK2YH500L3	196550	6.4 mm	440N
SLK2YH500L7	196551	6.4 mm	440N
SLK2YH500L2	196549	6.4 mm	440N


Thickness (T): 12.5 mm

Width (W): 19 mm

Height (H): 55 mm

Angle (a): 90 ° Max

DIAGRAMS

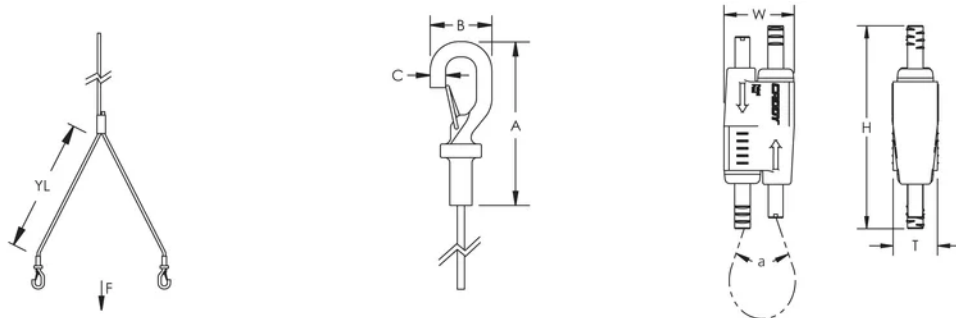

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răni corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

