

nVent CADDY Speed Link SLS with Hook



CERTIFICATIONS



CARACTERISTICI

Complete system includes wire, locking device and pre-assembled hook end fitting

Hooks to a wide range of nVent CADDY fasteners

Fastens to the building structure or hanging services by looping around and hooking to wire rope

Easy to remove for applications requiring maintenance

Spring latch helps provide secure connection

Insert cable through hole and use bottom side of hook as an end stop

Finger tightening of nut secures the locking device into position without tools

Installs in strut profiles without the need to insert fingers or tools into the strut

SPECIFICAȚII

Static Load Safety Factor:	5:1
Finish:	Electrogalvanized
Complies With:	SMACNA HVAC-DCS

Număr de catalog	SLS2L10	SLS2L2	SLS2L3	SLS3L10	SLS3L2	SLS3L3	SLS3L5

Article Number	196746	196742	196743	196752	196748	196749	196750
Material	Steel Zinc Alloy Polypropylene	Steel Zinc Alloy Polypropylene	Steel Zinc Alloy Polypropylene	Steel Zinc Alloy Polypropylene	Steel Zinc Alloy Polypropylene	Steel Zinc Alloy Polypropylene	Steel Zinc Alloy Polypropylene
Wire Rope Diameter	2 mm	2 mm	2 mm	3 mm	3 mm	3 mm	3 mm
Wire Rope Length	10m	2m	3m	10m	2m	3m	5m
A	57 mm	57 mm	57 mm	57.6 mm	57.6 mm	57.6 mm	57.6 mm
B	20 mm	20 mm	20 mm	23.2 mm	23.2 mm	23.2 mm	23.2 mm
C	5.5 mm	5.5 mm	5.5 mm	6.1 mm	6.1 mm	6.1 mm	6.1 mm
Height 1 (H1)	53mm	53mm	53mm	53mm	53mm	53mm	53mm
Height 2 (H2)	43.5mm	43.5mm	43.5mm	46.5mm	46.5mm	46.5mm	46.5mm
Thread Size (TS)	M8	M8	M8	M12	M12	M12	M12
Width (W)	16 mm	16 mm	16 mm	20 mm	20 mm	20 mm	20 mm
Hole Size (HS)	8 - 10 mm	8 - 10 mm	8 - 10 mm	12 - 14 mm	12 - 14 mm	12 - 14 mm	12 - 14 mm
Slot Size (SS)	8 x 6.5 mm - 8 x 10 mm	8 x 6.5 mm - 8 x 10 mm	8 x 6.5 mm - 8 x 10 mm	12 x 10 mm - 12 x 14 mm	12 x 10 mm - 12 x 14 mm	12 x 10 mm - 12 x 14 mm	12 x 10 mm - 12 x 14 mm
Thickness (T)	4 mm Max	4 mm Max	4 mm Max	6 mm Max	6 mm Max	6 mm Max	6 mm Max
Static Load	270N	270N	270N	670N	670N	670N	670N


DETALII SUPLIMENTARE DESPRE PRODUS

The 2 mm locking device is compatible with C-Channel Types E0 and E0L.

The 3 mm locking device is compatible with C-Channel Types E1, E2, E2L, E3, E4, E5, Strut Channel Type C, Slotted, Strut Channel Type A, Slotted, Strut Channel Type AS, Perforated, Strut Channel Type CC, Slotted, Strut Channel Type AA, Slotted.

Total load per wire on a multi-tier trapeze must not exceed static load.

DIAGRAMS

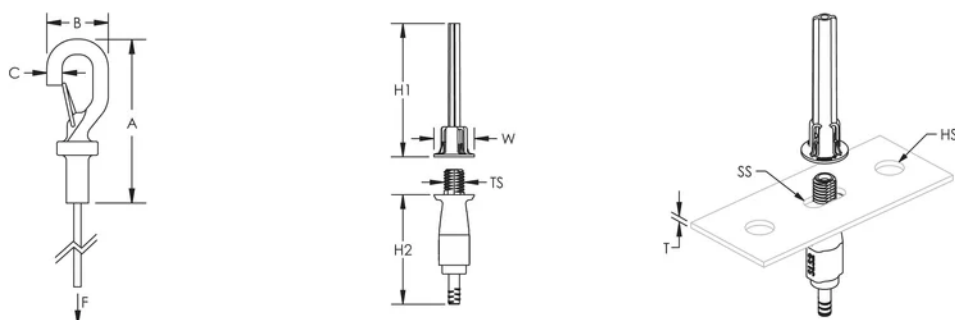

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

