


PEMSA Wire Basket Tray Cable Outlet

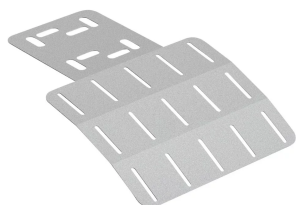

CERTIFICATIONS



CARACTERISTICI

Easy to install

Allows for easy exit angle adjustment (from 0 to 90 degrees)

SPECIFICAȚII

Material: Oțel

Table 1/2


Număr de catalog	Article Number	Color	Finish	Length (L)	Width 1 (W1)	Width 2 (W2)
WBTCBLOUTBA	820801	Black		216mm	85 mm	150 mm
WBTCBLOUT	820800		Pregalvanized	216mm	85 mm	150 mm

Table 2/2

Număr de catalog	Article Number	Thickness (T)	Hole Size 1 (HS1)	Hole Size 2 (HS2)	Certifications
------------------	----------------	---------------	-------------------	-------------------	----------------

WBTCBLOUTBA	820801	1.5 mm	7 - 20 mm	3 - 30 mm	
WBTCBLOUT	820800	1.5 mm	7 - 20 mm	3 - 30 mm	CE, CADDY EU WBT CBL

DIAGRAMS

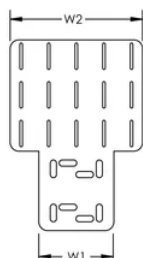

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

