


RS Retrofit Retainer Strap



The nVent CADDY RS Retrofit Retainer Strap is designed to assist in the securement of beam clamps and other flanges to metal structures. Due to the post-installation function, the RS Retrofit Retainer Strap can be added to pre-existing hanging systems without dismantling any clamps or threaded rods already in place. With a teardrop-shaped opening to lock onto the rod, contractors can be confident that components will not shift during installation and will retain their integrity even in the case of a seismic event.

CERTIFICATIONS

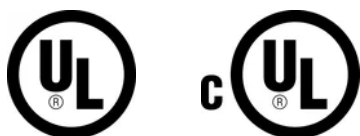

CARACTERISTICI

Ideal for both new and existing applications

Designed for use with the nVent CADDY Beam Clamps and Accessories

Can be secured to either the set screw or threaded rod

Large teardrop-shaped opening is compatible with multiple threaded rod diameters, significantly reducing inventory

Provides a secure attachment in seismic zones and complies with NFPA® requirements

SPECIFICAȚII

Finish: Pregalvanized

Material: Oțel

Table 1/2

Număr de catalog	Article Number	Length (L)	Width (W)	Thickness (T)	Rod Size (RS)	Hole Size (HS)
RS06	590250	165.1mm	44.5 mm	1.5 mm	M10, M12, M16, M20	28.6 mm
RS08	590251	215.9mm	44.5 mm	1.5 mm	M10, M12, M16, M20	28.6 mm

Număr de catalog	Article Number	Length (L)	Width (W)	Thickness (T)	Rod Size (RS)	Hole Size (HS)
RS10	590252	266.7mm	44.5 mm	1.5 mm	M10, M12, M16, M20	28.6 mm
RS12	590253	317.5mm	44.5 mm	1.5 mm	M10, M12, M16, M20	28.6 mm
RS14	590254	368.3mm	44.5 mm	1.5 mm	M10, M12, M16, M20	28.6 mm
RS16	590255	419.1mm	44.5 mm	1.5 mm	M10, M12, M16, M20	28.6 mm
RS18	590256	469.9mm	44.5 mm	1.5 mm	M10, M12, M16, M20	28.6 mm


Table 2/2

Număr de catalog	Article Number	A
RS06	590250	82.3 mm
RS08	590251	82.3 mm
RS10	590252	82.3 mm
RS12	590253	82.3 mm
RS14	590254	82.3 mm
RS16	590255	82.3 mm
RS18	590256	82.3 mm

DETALII SUPLIMENTARE DESPRE PRODUS

Add 2" to width of flange to determine minimum length strap required.

 DIAGRAMS



AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

