


Universal Structural Attachment

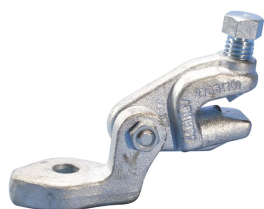

CERTIFICATIONS



Korea Fire Institute



CARACTERISTICI

Universal design allows one product to attach directly to concrete, wood, bar joist or I-beam adapters

Snap-off bolt head helps enable easy installation and inspection of seismic sway braces

Use for both lateral and longitudinal sway brace applications

Works with 1" through 2" brace pipes and 1/4" angle iron braces to reduce inventory

Center bolt does not require tightening

Meets NFPA®-13 requirements for seismic sway bracing

Meets CEN/TS 17551:2021 requirements for Seismic Sway Bracing

SPECIFICAȚII

Table 1/2

Număr de catalog	Article Number	Material	Finish	Hole Size (HS)	A	B
CSBUNIV050EG	404407	Cast Iron	Electrogalvanized	14 mm	133.4 mm	101.6 mm

Număr de catalog	Article Number	Material	Finish	Hole Size (HS)	A	B
CSBUNIV075EG	404409	Cast Iron	Electro galvaniz ed	21 mm	133.4 mm	101.6 mm


Table 2/2

Număr de catalog	Article Number	C	Certifications
CSBUNIV050EG	404407	41.4 mm	UL, FM Approved, Seismic, AON Fire Protection, Rigid Seismic, Korea Fire Institute, Rigid Seismic, KOR, OSHPD, cUL
CSBUNIV075EG	404409	41.4 mm	cUL, AON Fire Protection, Rigid Seismic, UL, FM Approved, Seismic, OSHPD

UL Loads		
Part number	Brace Member	Rating
CSBUNIV050EG	25 mm - 50 mm EN10255H	6094 N
CSBUNIV075EG	25 mm - 50 mm EN10255H	8896 N

FM Loads					
Brace Type	Service Pipe Size	Horizontal Capacity per Installation Angle from Vertical			
		30° - 44°	45° - 59°	60° - 74°	75° - 90°
Pipe	N/A	7,205 N	10,230 N	12,545 N	13,965 N

DIAGRAMS

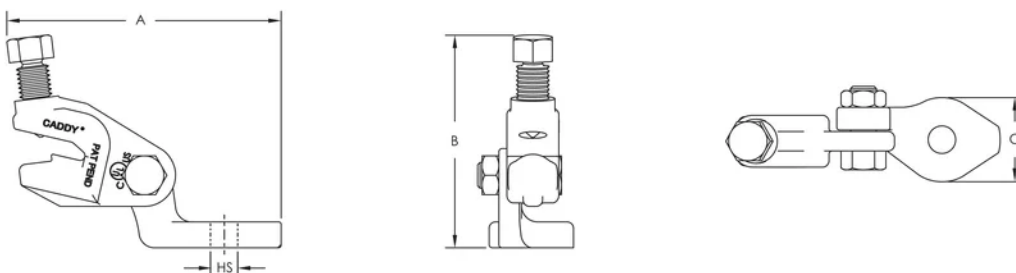

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

