

# 19" Front Panel

## Data Solutions

Front panels made of Aluminum.



### CERTIFICATIONS



### CARACTERISTICI

Aluminum, 4 or 3 mm thick, with Anodized or Painted finish

### SPECIFICAȚII

<b>Rack Width:</b>	95HP
<b>Material:</b>	Aluminiu
<b>Accessory Type:</b>	Front panel
<b>Product Type:</b>	Front Panel

Table 1/3

Număr de catalog	Rack Height	Depth (D)	Mounting	Finish	Front Finish	Package Quantity
30118-299	1U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1

Număr de catalog	Rack Height	Depth (D)	Mounting	Finish	Front Finish	Package Quantity
30118-948	1U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30219-098	1U	3mm	Screw-on Front	Anodized	Anodized	1
40304-074	1U	4mm	Screw-on Front	Anodized	Anodized	1
30118-301	2U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30118-302	3U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30118-303	4U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30118-304	5U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30118-305	6U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30118-306	7U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30118-307	8U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30118-308	9U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30118-309	10U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30118-949	2U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30118-950	3U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30118-951	4U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30118-952	5U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30118-953	6U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30118-954	7U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1

Număr de catalog	Rack Height	Depth (D)	Mounting	Finish	Front Finish	Package Quantity
30118-955	8U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30118-956	9U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30118-957	10U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30219-101	2U	3mm	Screw-on Front	Anodized	Anodized	1
30219-104	3U	3mm	Screw-on Front	Anodized	Anodized	1
30219-107	4U	3mm	Screw-on Front	Anodized	Anodized	1
30219-110	5U	3mm	Screw-on Front	Vopsit Pulbere	Anodized	1
30219-113	6U	3mm	Screw-on Front	Anodized	Anodized	1
30219-137	7U	3mm	Screw-on Front	Anodized	Anodized	1
30219-138	8U	3mm	Screw-on Front	Anodized	Anodized	1
30219-143	9U	3mm	Screw-on Front	Anodized	Anodized	1
30219-144	10U	3mm	Screw-on Front	Anodized	Anodized	1
40304-075	2U	4mm	Screw-on Front	Anodized	Anodized	1
40304-076	3U	4mm	Screw-on Front	Anodized	Anodized	1
40304-077	4U	4mm	Screw-on Front	Anodized	Anodized	1
40304-078	5U	4mm	Screw-on Front	Anodized	Anodized	1
40304-079	6U	4mm	Screw-on Front	Anodized	Anodized	1
40304-080	7U	4mm	Screw-on Front	Anodized	Anodized	1

Număr de catalog	Rack Height	Depth (D)	Mounting	Finish	Front Finish	Package Quantity
40304-081	8U	4mm	Screw-on Front	Anodized	Anodized	1
40304-082	9U	4mm	Screw-on Front	Anodized	Anodized	1
40304-083	10U	4mm	Screw-on Front	Anodized	Anodized	1

Table 2/3

Număr de catalog	Rear Finish	Treated Edges	Color Code	EMC Shielding	Height (H)	Type
30118-299	Painted		RAL 7035	No	43.6mm	19" Front Panel
30118-948	Painted		RAL 7021	No	43.6mm	19" Front Panel
30219-098	Anodized	No		No	43.6mm	19" Front Panel
40304-074	Anodized	Yes		No	43.6mm	19" Front Panel
30118-301	Painted		RAL 7035	No	88.1mm	19" Front Panel
30118-302	Painted		RAL 7035	No	132.5mm	19" Front Panel
30118-303	Painted		RAL 7035	No	177mm	19" Front Panel
30118-304	Painted		RAL 7035	No	221.4mm	19" Front Panel
30118-305	Painted		RAL 7035	No	265.9mm	19" Front Panel
30118-306	Painted		RAL 7035	No	310.3mm	19" Front Panel
30118-307	Painted		RAL 7035	No	354.8mm	19" Front Panel
30118-308	Painted		RAL 7035	No	399.2mm	19" Front Panel
30118-309	Painted		RAL 7035	No	443.7mm	19" Front Panel

Număr de catalog	Rear Finish	Treated Edges	Color Code	EMC Shielding	Height (H)	Type
30118-949	Painted		RAL 7021	No	88.1mm	19" Front Panel
30118-950	Painted		RAL 7021	No	132.5mm	19" Front Panel
30118-951	Painted		RAL 7021	No	177mm	19" Front Panel
30118-952	Painted		RAL 7021	No	221.4mm	19" Front Panel
30118-953	Painted		RAL 7021	No	265.9mm	19" Front Panel
30118-954	Painted		RAL 7021	No	310.3mm	19" Front Panel
30118-955	Painted		RAL 7021	No	354.8mm	19" Front Panel
30118-956	Painted		RAL 7021	No	399.2mm	19" Front Panel
30118-957	Painted		RAL 7021	No	443.7mm	19" Front Panel
30219-101	Anodized	No		No	88.1mm	19" Front Panel
30219-104	Anodized	No		No	132.5mm	19" Front Panel
30219-107	Anodized	No		No	177mm	19" Front Panel
30219-110	Anodized	No		No	221.4mm	19" Front Panel
30219-113	Anodized	No		No	265.9mm	19" Front Panel
30219-137	Anodized	No		No	310.3mm	19" Front Panel
30219-138	Anodized	No		No	354.8mm	19" Front Panel
30219-143	Anodized	No		No	399.2mm	19" Front Panel
30219-144	Anodized	No		No	443.7mm	19" Front Panel

Număr de catalog	Rear Finish	Treated Edges	Color Code	EMC Shielding	Height (H)	Type
40304-075	Anodized	Yes		No	88.1mm	19" Front Panel
40304-076	Anodized	Yes		No	132.5mm	19" Front Panel
40304-077	Anodized	Yes		No	177mm	19" Front Panel
40304-078	Anodized	Yes		No	221.4mm	19" Front Panel
40304-079	Anodized	Yes		No	265.9mm	19" Front Panel
40304-080	Anodized	Yes		No	310.3mm	19" Front Panel
40304-081	Anodized	Yes		No	354.8mm	19" Front Panel
40304-082	Anodized	Yes		No	399.2mm	19" Front Panel
40304-083	Anodized	Yes		No	443.7mm	19" Front Panel

Table 3/3

Număr de catalog	Width (W)
30118-299	483mm
30118-948	483mm
30219-098	483mm
40304-074	483mm
30118-301	483mm
30118-302	483mm
30118-303	483mm
30118-304	483mm

Număr de catalog	Width (W)
30118-305	483mm
30118-306	483mm
30118-307	483mm
30118-308	483mm
30118-309	483mm
30118-949	483mm
30118-950	483mm
30118-951	483mm
30118-952	483mm
30118-953	483mm
30118-954	483mm
30118-955	483mm
30118-956	483mm
30118-957	483mm
30219-101	483mm
30219-104	483mm
30219-107	483mm
30219-110	483mm


Număr de catalog	Width (W)
30219-113	483mm
30219-137	483mm
30219-138	483mm
30219-143	483mm
30219-144	483mm
40304-075	483mm
40304-076	483mm
40304-077	483mm
40304-078	483mm
40304-079	483mm
40304-080	483mm
40304-081	483mm
40304-082	483mm
40304-083	483mm

## DETALII SUPLIMENTARE DESPRE PRODUS

Please order 19" assembly kit separately.



## DIAGRAMS

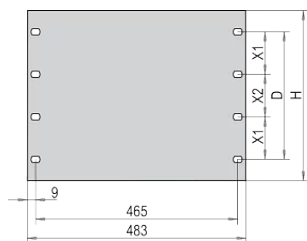

## AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.



Portofoliul nostru puternic de mărci:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**