

# Branch Line Restraint Pipe Attachment

## Data Solutions



### CERTIFICATIONS



### CARACTERISTICI

Accepts 3/8" or 1/2" (M10 or M12) threaded rod

Quick grip clamp simplifies measuring and cutting of threaded rod

Eliminates need to cut threaded rod to exact dimensions

Works with rough-cut threaded rod and eliminates pipe-side deburring

Can be installed with threaded rod above or below the service pipe

Shear-off head helps ensure correct torque and simplifies inspection

### SPECIFICAȚII

**Finish:** Electrogalvanized

**Material:** Oțel

Table 1/2


Număr de catalog	Article Number	NB/DN	Outer Diameter (OD)	Rod Size (RS)	Height (H)	Length (L)
------------------	----------------	-------	---------------------	---------------	------------	------------

CSBBRP0100E G	404477	25	33.4mm	10, 12	73.7mm	41.4mm
CSBBRP0125E G	404478	32	42.2mm	10, 12	82.6mm	50mm
CSBBRP0150E G	404479	40	48.3mm	10, 12	88.9mm	56.1mm
CSBBRP0200E G	404480	50	60.3mm	10, 12	100.3mm	68.3mm

Table 2/2

Număr de catalog	Article Number	Width (W)
CSBBRP0100EG	404477	22.2mm
CSBBRP0125EG	404478	22.2mm
CSBBRP0150EG	404479	22.2mm
CSBBRP0200EG	404480	22.2mm

## DIAGRAMS

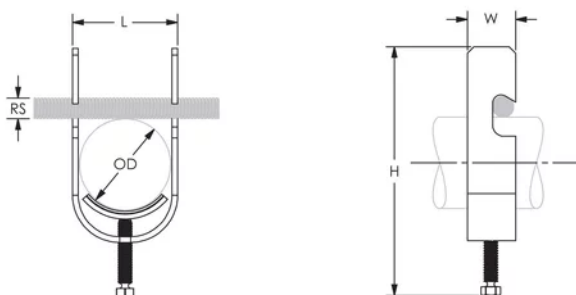

## AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răni corporale grave și moarte și/sau poate anula garanția dvs.



Portofoliul nostru puternic de mărci:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**