

Branch Line Restraint Structure Attachment to Steel

Data Solutions



CERTIFICATIONS



CARACTERISTICI

Swivel barrel nut accepts 3/8" or 1/2" (M10 or M12) threaded rod

Attaches to steel members with self-drilling/tapping screw

SPECIFICAȚII

Table 1/2

Număr de catalog	Article Number	Material	Finish	Rod Size (RS)	Flange Thickness (FT)	Height (H)
CSBBRS1MEG	402239	Oțel	Electro galvaniz ed	10, 12	2.7 – 12.7mm	28.2mm

Table 2/2


Număr de catalog	Article Number	Length (L)	Width (W)	Screw Diameter (Sc)	Screw Length (L)
------------------	----------------	------------	-----------	---------------------	------------------

CSBBRS1MEG	402239	40.4mm	26.9mm	2.7mm	32mm
------------	--------	--------	--------	-------	------

DETALII SUPLIMENTARE DESPRE PRODUS

Branch line structural attachments are for restraint only and not for the hanging of fire sprinkler piping.

DIAGRAMS

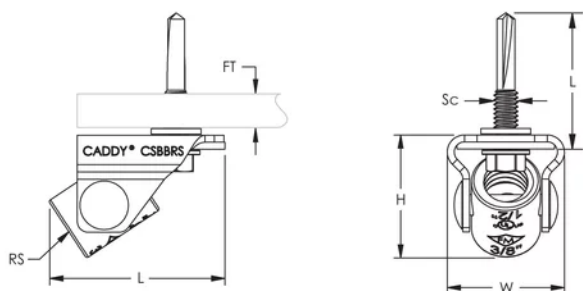

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE