


Electrical Earth Bar, Bare, 26 Connections, 0 Number of Disconnects, 1,500 mm

Data Solutions

NUMĂR DE CATALOG

EEB26C506D0A

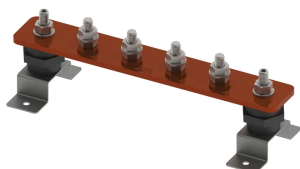

CARACTERISTICI

Provides a convenient, single-point grounding and bonding location

Busbars with disconnect links allow for convenient testing of the earth termination system

High conductivity, hard drawn, electrolytic tough pitch copper per EN 13601

Includes halogen-free polyamide insulators, stainless steel (EN 1.4401) hardware and mounting brackets

Custom bars can be designed and manufactured to customer specifications

ATTRIBUTE PRODUS

Complies With: IEC® EN 62561-1:2017 Class H

Material: Copper

Finish: Bare

Number of Connections: 26

Number of Disconnects: 0

Thread Size (TS): M10

Height (H): 94mm

Length (L): 1500mm

Width 1 (W1): 100mm

Width 2 (W2): 50mm

Thickness (T): 6mm

A: 50mm

Unit Weight: 6.44kg

DETALII SUPLIMENTARE DESPRE PRODUS

Tinned finish is 8 microns according to ASTM B545 Service Class "C" for corrosive environments.

DIAGRAMS



AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE