


Joint Bond T8 Complete Welder Pair, Power, 50 mm² Ropelay

Data Solutions

NUMĂR DE CATALOG

PBCT8X3

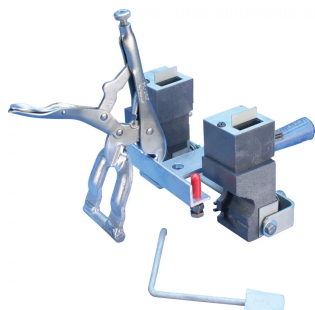

CARACTERISTICI

Complete welder assembly provides a convenient means of attaching jumper bonds to the head of the rail

Connection is made within the confines of the splice plate

Includes mold cleaner and flint ignitor

ATTRIBUTE PRODUS

Material: Graphite; Oțel; Thermoplastic

Rail Type: 85 lb to 141 lb T-Rail Sections

Bond Terminal Style: C

Conductor Size: 50 mm² Ropelay

Conductor Outer Diameter, Nominal: 9.13mm

Bond Length: 177.8mm

Welder Style: T8

Mold Only: No

Replacement Mold: PBCX3

Welding Material: PB45, Sold Separately

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

⚠ WARNING: This product can expose you to chemicals including diisononyl phthalate, which is known to the State of California to cause cancer. For more information go to www.P65Warnings.ca.gov.



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE