

PEMSA Wire Basket Tray Center Support

Data Solutions



CERTIFICATIONS



CARACTERISTICI

Ideal for tray widths up to 200mm

Side load access for cable installation

IEC 61537 load rating and earthing compliant

SPECIFICAȚII

Finish: Electrogalvanized

Material: Oțel

Table 1/2


Număr de catalog	Article Number	Color	Length (L)	Width (W)	Height (H)	Hole Size (HS)
WBTCTRSPT M6	820400		59mm	35mm	5mm	6mm

Număr de catalog	Article Number	Color	Length (L)	Width (W)	Height (H)	Hole Size (HS)
WBTCTRSPT M10	820420		59mm	35mm	5mm	8 – 10mm
WBTCTRSPT M10BG	820421	Black	59mm	35mm	5mm	8 – 10mm

Table 2/2

Număr de catalog	Article Number	Certifications
WBTCTRSPTM6	820400	CE, CADDY EU WBT QC
WBTCTRSPTM10	820420	CE, CADDY EU WBT QC, ANOR EU WTB EG S4 BG
WBTCTRSPTM10BG	820421	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT QC

DIAGRAMS

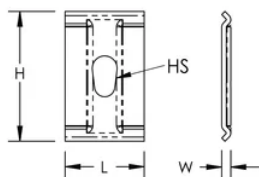

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE