


Varistar CP Double Steel Door, Perforated, 3-Point Locking

Data Solutions

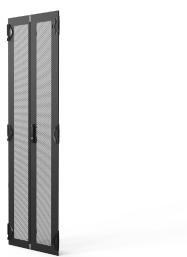

Perforated Varistar CP steel double door with 3-point locking for applications with IP 20 protection

CARACTERISTICI

Double perforated steel door with 3 point locking for IP 20 protection class

Lever handle with key insert (2 keys)

Opening angle 180°

Standard fitting, lock on right-hand door

Can be retrofitted with lever handle 24630003 and DIN profile half cylinder with keys or push button

SPECIFICAȚII

Locking Type: 3-Point Locking

Product Type: Cabinet Door

Protection Rating: IP20

Material: Oțel

Table 1/2

Număr de catalog	Rack Height	Height	Width	Package Quantity	Color	Color Code
21630-020	42U	2000mm	600mm	1	Black Grey	RAL 7021
21630-021	47U	2200mm	600mm	1	Black Grey	RAL 7021

Număr de catalog	Rack Height	Height	Width	Package Quantity	Color	Color Code
21630-022	52U	2450mm	600mm	1	Black Grey	RAL 7021
21630-027	42U	2000mm	800mm	1	Black Grey	RAL 7021
21630-028	47U	2200mm	800mm	1	Black Grey	RAL 7021
21630-029	52U	2450mm	800mm	1	Black Grey	RAL 7021
21630-448	24U	1200mm	600mm	1	Black Grey	RAL 7021
21630-449	24U	1200mm	800mm	1	Black Grey	RAL 7021
21630-450	29U	1400mm	600mm	1	Black Grey	RAL 7021
21630-451	29U	1400mm	800mm	1	Black Grey	RAL 7021
21630-452	33U	1600mm	600mm	1	Black Grey	RAL 7021
21630-453	33U	1600mm	800mm	1	Black Grey	RAL 7021
21630-454	38U	1800mm	600mm	1	Black Grey	RAL 7021
21630-455	38U	1800mm	800mm	1	Black Grey	RAL 7021

Table 2/2

Număr de catalog	Complies With	Finish	Type	Works With
21630-020	IEC 61587-1, IEC 61587-3	Vopsit Pulbere	Steel Double Door, Perforated	Varistar CP
21630-021	IEC 61587-1, IEC 61587-3	Vopsit Pulbere	Steel Double Door, Perforated	Varistar CP
21630-022	IEC 61587-1, IEC 61587-3	Vopsit Pulbere	Steel Double Door, Perforated	Varistar CP
21630-027	IEC 61587-1, IEC 61587-3	Vopsit Pulbere	Steel Double Door, Perforated	Varistar CP
21630-028	IEC 61587-1, IEC 61587-3	Vopsit Pulbere	Steel Double Door, Perforated	Varistar CP

Număr de catalog	Complies With	Finish	Type	Works With
21630-029	IEC 61587-1, IEC 61587-3	Vopsit Pulbere	Steel Double Door, Perforated	Varistar CP
21630-448	IEC 61587-1, IEC 61587-3	Vopsit Pulbere	Steel Double Door, Perforated	Varistar CP
21630-449	IEC 61587-1, IEC 61587-3	Vopsit Pulbere	Steel Double Door, Perforated	Varistar CP
21630-450	IEC 61587-1, IEC 61587-3	Vopsit Pulbere	Steel Double Door, Perforated	Varistar CP
21630-451	IEC 61587-1, IEC 61587-3	Vopsit Pulbere	Steel Double Door, Perforated	Varistar CP
21630-452	IEC 61587-1, IEC 61587-3	Vopsit Pulbere	Steel Double Door, Perforated	Varistar CP
21630-453	IEC 61587-1, IEC 61587-3	Vopsit Pulbere	Steel Double Door, Perforated	Varistar CP
21630-454	IEC 61587-1, IEC 61587-3	Vopsit Pulbere	Steel Double Door, Perforated	Varistar CP
21630-455	IEC 61587-1, IEC 61587-3	Vopsit Pulbere	Steel Double Door, Perforated	Varistar CP

DETALII SUPLIMENTARE DESPRE PRODUS

24U - 33U IP20 doors have 2 hinges, 38U - 52U IP20 doors have 3 hinges to ensure robust IP20 closing structures for taller cabinets

Please order lever handle 24630003 and the DIN lock separately if you want to replace the 1333 DIN lock lever handle

Please purchase the grounding kit separately.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răni corporale grave și moarte și/sau poate anula garanția dvs.



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE