

Aircraft Grounding Receptacle with Bar Attachment Point



CARACTERISTICI

Castings for use in static grounding systems of refueling areas

Suitable as a combination tie down and static ground point

Easily connected to grounding system conductor and/or ground rods

Designed for simple installation with flush paved surfaces

Compatible with nVent ERICO Cadweld connections


SPECIFICAȚII

Material: Phosphor Bronze

Table 1/1

Număr de catalog	Article Number	Diameter 1 (Ø1)	Diameter 2 (Ø2)	Depth (D)	Attachment Point (AP)	Connection Type
B167	165230	120 mm	112 mm	184.2mm	38 mm Diameter Bar	RA, RB
B166	165220	98 mm	88.9 mm	133.35mm	19 mm Diameter Bar	RA, RB

DIAGRAMS

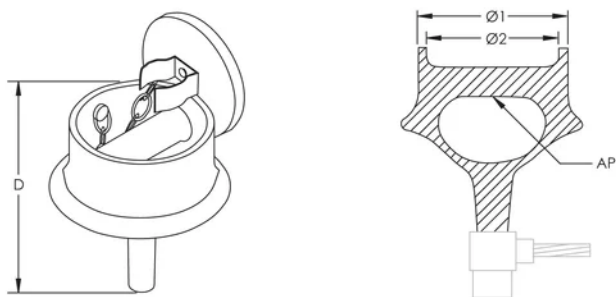

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE