


Cast Two Bolt Beam Bonding Clamp

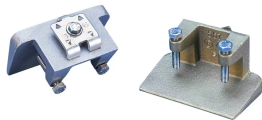

CERTIFICATIONS



CARACTERISTICI

Clamp for bonding cable to flat metal objects such as I-beams, angle irons and channel irons

Listed to UL® 96

SPECIFICAȚII

Conductor Size, UL: Class 1 - Class 2 (4/0 Max)

Table 1/2


Număr de catalog	Material	Flange Thickness (FT)	Depth (D)	Height (H)	Width (W)	Contact Area
LPA557	Aluminiu	25.4 mm Max	69.85mm	50.8 mm	101.6 mm	51.61 mm ² Min
LPC557	Copper	25.4 mm Max	69.85mm	50.8 mm	101.6 mm	51.61 mm ² Min

Table 2/2

Număr de catalog	Unit Weight
------------------	-------------

LPA557	0.32 kg
LPC557	0.93 kg

DIAGRAMS

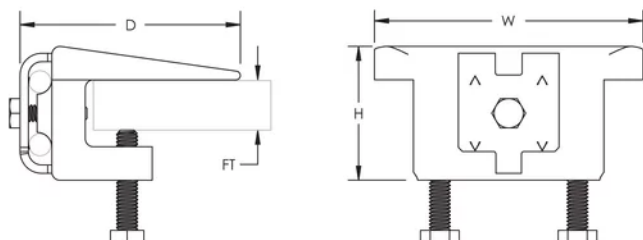

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE