 
 


Earthbridge B164, Four Stud, Solid Round Steel, 90° Angle



Earthbridges are assemblies made from a high-quality conductive earthpoint (connecting terminal) and various types of conductors. The nVent ERICO Cadweld exothermic connection process is used to combine them together, forming a highly corrosion resistant and long-lasting assembly.

DIAGRAMS



CARACTERISTICI

Long-lasting design

Low ground resistance and impedance

Superior electrical conductivity and resistance to corrosion

Electrically and mechanically robust and reliable

Easy to install

SPECIFICAȚII

Earthpoint Type: B164, Four Stud

Conductor Type: Solid Round Steel, 90° Angle

Table 1/3

Număr de catalog	Material	Type	Conductor Size	Length (L)	Depth 1 (D1)	Depth 2 (D2)
------------------	----------	------	----------------	------------	--------------	--------------

BF12K12P050H G	Copper, Oțel	BFKP	12 mm Diameter Solid	500mm	44.5mm	85mm
BF12K12P050H	Copper, Oțel	BFKP	12 mm Diameter Solid	500mm	44.5mm	85mm

Table 2/3

Număr de catalog	Width 1 (W1)	Width 2 (W2)	Thread Size (TS)	Angle (a)	Rebar Assembly Type	Hardware Included
BF12K12P050H G	44.5 mm	85 mm	M12	90 °	Arc Welding to Rebar	Yes
BF12K12P050H	44.5 mm	85 mm	M12	90 °	Arc Welding to Rebar	Yes

Table 3/3


Număr de catalog	Earthbridge Application	Complies With
BF12K12P050HG	Tunnel	EN IEC® 62561-1 Class H 100kA
BF12K12P050H	Tunnel	EN IEC® 62561-1 Class H 100kA

DETALII SUPLIMENTARE DESPRE PRODUS

Includes (4) brass bolts, (4) brass washers, (4) plastic caps, and (1) protective label.

DB-16-C-70-S-050-C		
DB	Earth Point	DB: 1 hole BT: 2 holes BF: 4 holes LU: M16 lug TA: tape
16	Thread Size	10: M10 12: M12 16: M16 40: Tape 40x5mm 30: Tape 30x4mm
C	Conductor Type	K: Steel Rond C: Y/G Cable T: Steel Bar F: Steel Bar 4mm N: NYY-O Cable H: N2XH-0 Cable
70	Conductor Size	12: D12mm 16: D16mm 30: 30x4mm 40: 40x5mm 50: 50mm ² 70: 70mm ² 95: 95mm ²
S	Conductor Angle	S: 0° P: 90° A: 45°
050	Length (cm)	xxx
x	Termination (option if cable)	SR: Solid Round EP: Earthpoint perpendicular ES: Earthpoint straight TA: Tape of 100mm TP: Tape of 150mm LU: M16 lug
x	Bolts & Washer	- : No Hardware H: With Hardware
C	Packaging	- : by unit (Made-to-Stock) C: 5 pieces (Made-to-Order) G: 25 pieces (Made-to-Order)

DIAGRAMS

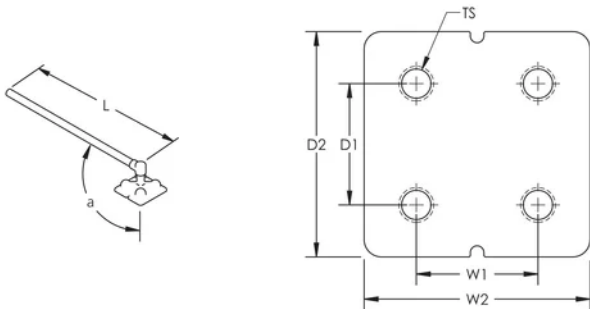

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE