

ESE Air Terminal for Remote Tester



The nVent ERICO Early Streamer Emission (ESE) Air Terminal for Remote Tester generates controlled magnitude and frequency pulses at the tip of the terminal during high static fields before a lightning discharge. Due to the internal control circuit, the nVent ERICO ESE Air Terminal for Remote Tester enables early launching of an upward leader compared to other passive components. When paired with the nVent ERICO ESE Air Terminal Remote Tester, the need for on-site manual testing is eliminated and creates a more autonomous, continuous monitoring solution.

CARACTERISTICI

Designed and tested to NF C 17-102 and similar standards

Superior corrosion resistance, even in high salinity environments

Quick and easy installation

Compatible with nVent ERICO ESE Air Terminal Remote Tester

Suitable for use with a variety of downconductor systems including tape and stranded conductors in addition to insulated downconductors such as nVent ERICO ISONV and nVent ERICO Ericore conductors

SPECIFICAȚII


Table 1/2

Număr de catalog	Complies With	Connects To	Triggered Advance, ΔT	Temperature	Diameter ($\varnothing$)	Height (H)
SI60I316RT	NF C17-102:2011, NP 4426:2013, UNE 21186:2011	ESEAT Remote Tester (SIREMOTETES TER)	60 μ s	120 °C Max	28 mm	684.6 mm

Table 2/2

Număr de catalog	Material	Thread Size (TS)	Unit Weight
SI60I316RT	Stainless Steel 316L (EN 1.4404)	MF25	1.56 kg

DIAGRAMS

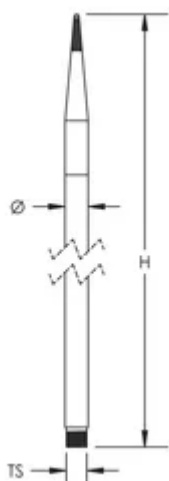

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE