

Ground Rod Clamp with Prefabricated Pigtail



CARACTERISTICI

Prefabricated assembly including grounding clamp with pigtail

Fast and simple installation requires only a hammer

SPECIFICAȚII


Material: Copper

Insulation: Green and Yellow Insulated Cable

Table 1/1

Număr de catalog	Article Number	Ground Rod Diameter, Nominal	Length (L)	Pigtail Length	Conductor Size	Unit Weight
EPT1225300	158610	1/2"	70mm	300mm	25 mm ² Stranded	0.5 kg
EPT1450350	158290	5/8"	75mm	350mm	50 mm ² Stranded	0.5 kg
EPT1425350	158675	5/8"	75mm	350mm	25 mm ² Stranded	0.5 kg

DIAGRAMS

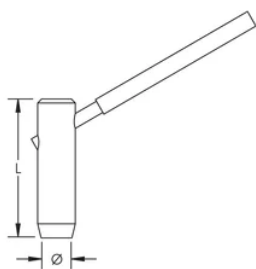

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE