


# Ground Rod Clamp, Rod to Conductor, Stainless Steel



## CERTIFICATIONS

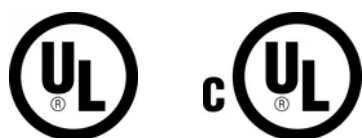

## CARACTERISTICI

Unique stamped body design will not crack from excessive torque

Provides a greater surface area contact to allow improved performance of the connector

Compatible with copper, copper bonded, galvanized, stainless steel, rebar and plain steel ground rods and electrodes

## SPECIFICAȚII


Table 1/2

| Număr de catalog | Article Number | Material                        | Torque (TQ)      | Ground Rod Diameter, Nominal | Ground Rod Diameter, Actual (Ø) | Conductor Size                                               |
|------------------|----------------|---------------------------------|------------------|------------------------------|---------------------------------|--------------------------------------------------------------|
| SP58             | 158185         | Stainless Steel 304 (EN 1.4301) | 16.90 - 33.9 N·m | 1/2" - 5/8"                  | 12.7 - 15.9 mm                  | #10 Stranded - #2 Stranded, 6 mm² Stranded - 25 mm² Stranded |

Table 2/2

| Număr de catalog | Article Number | Wrench Size |
|------------------|----------------|-------------|
| SP58             | 158185         | 1/2"        |

## DIAGRAMS

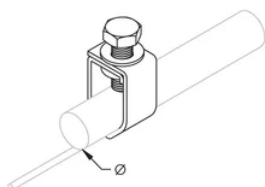

## AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

**⚠ WARNING:** This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**