

Ground Rod Driving Point for Ground Rod, Sectional Internal Thread



CARACTERISTICI

Threaded ground rod driving point for use only with internally threaded ground rods


SPECIFICAȚII

Material: Oțel

Table 1/1

Număr de catalog	Article Number	For Use With	Length (L)	Thread Length (TL)	Diameter (Ø)	Thread Size (TS)
SPK15	710120	SSR16 and SCR15 Internally Threaded Ground Rods	42mm	20mm	15 mm	M10
SPK20	710130	SSR20 Internally Threaded Ground Rod	51mm	20mm	20 mm	M10

DIAGRAMS

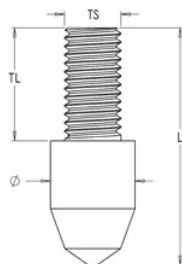

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE