


Insulated Tape Conductor

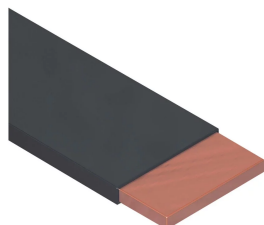

CARACTERISTICI

Provides a path to ground for lightning currents

Available in various colors to match building or design requirements

SPECIFICAȚII

Table 1/2

Număr de catalog	Article Number	Insulation Thickness	Material	Conductor Width	Conductor Thickness	Length
CTGY25325	710645	1.0 - 1.5 mm	Copper, Polyvinylchloride	25 mm	3 mm	25m

Table 2/2

Număr de catalog	Article Number	Color	Unit Weight
CTGY25325	710645	Gray	0.77 kg

DETALII SUPLIMENTARE DESPRE PRODUS

Unit weight is per meter (3.28').

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și

avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE