

ISOnV Mast Stand



CARACTERISTICI

Used to support ISOnV mast assemblies with an outlet

Masts and cables can be assembled horizontally, and stood up into this stand from a level position

SPECIFICAȚII

Material: Stainless Steel 304 (EN 1.4301)


Table 1/1

Număr de catalog	Length (L)	Height (H)	Width (W)
ISONVSTAND10	1240mm	600 mm	860 mm
ISONVSTAND15	1730mm	900 mm	1205 mm
ISONVSTAND25	2860mm	1450 mm	2005 mm

DETALII SUPLIMENTARE DESPRE PRODUS

ISOnV Mast Stand must be installed with four concrete block supports.

DIAGRAMS

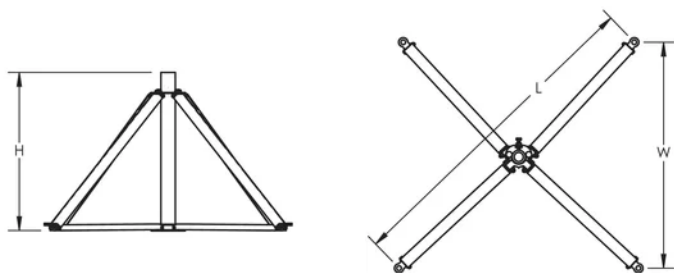

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE