


Joint Bond T6 Complete Welder Pair, Signal

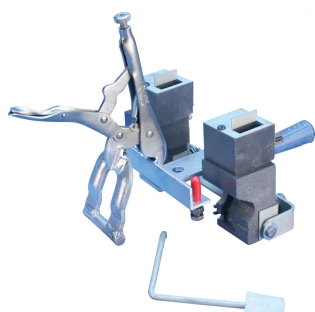

CARACTERISTICI

Complete welder assembly provides a convenient means of attaching jumper bonds to the head of the rail, across the joint

Connection is made within the confines of the splice bar

Includes mold cleaner

SPECIFICAȚII

Rail Type: 85 lb to 141 lb T-Rail Sections

Table 1/2

Număr de catalog	Article Number	Material	Bond Terminal Style	Conductor Size	Conductor Outer Diameter, Nominal	Bond Length
SBHFT6A		Steel, Graphite, Thermoplastic	Head Free	3/16" Bondstrand	4.76mm	165.1mm
SBHFT6C		Steel, Graphite, Thermoplastic	Head Free	3/16" Bondstrand	4.76mm	190.5mm
SBHFT6D		Steel, Graphite, Thermoplastic	Head Free	3/16" Bondstrand	4.76mm	247.7mm
SBTBT6A		Steel, Graphite, Thermoplastic	1" Tab	3/16" Bondstrand	4.76mm	165.1mm
SBTBT6C		Steel, Graphite, Thermoplastic	3/4" Tab	3/16" Bondstrand	4.76mm	190.5mm

Număr de catalog	Article Number	Material	Bond Terminal Style	Conductor Size	Conductor OuterDiameter, Nominal	Bond Length
SBTBT6D	715408	Steel, Graphite, Thermoplastic	1" Tab	3/16" Bondstrand	4.76mm	247.7mm
SBXST6A		Steel, Graphite, Thermoplastic	3/4" XS	3/16" Bondstrand	4.76mm	165.1mm
SBXST6C	165570	Steel, Graphite, Thermoplastic	3/4" XS	3/16" Bondstrand	4.76mm	190.5mm
SBXST6D		Steel, Graphite, Thermoplastic	3/4" XS	3/16" Bondstrand	4.76mm	247.7mm
SBST6X2	222628	Steel, Graphite, Thermoplastic	1" Tab	35 mm ² Ropelay	7.75mm	177.8mm
SBHFT6B		Steel, Graphite, Thermoplastic	Head Free	5/16" Bondstrand	7.95mm	177.8mm
SBTBT6B		Steel, Graphite, Thermoplastic	1" Tab	5/16" Bondstrand	0.79mm	177.8mm
SBTBT6E		Steel, Graphite, Thermoplastic	1" Tab	5/16" Bondstrand	0.79mm	247.7mm

Table 2/2

Număr de catalog	Article Number	Welder Style
SBHFT6A		T6
SBHFT6C		T6
SBHFT6D		T6
SBTBT6A		T6
SBTBT6C		T6
SBTBT6D	715408	T6
SBXST6A		T6
SBXST6C	165570	T6

Număr de catalog	Article Number	Welder Style
SBXST6D		T6
SBST6X2	222628	T6
SBHFT6B		T6
SBTBT6B		T6
SBTBT6E		T6

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

⚠ WARNING: This product can expose you to chemicals including diisononyl phthalate, which is known to the State of California to cause cancer. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE