


Joint Bond T8 Complete Welder Pair, Power

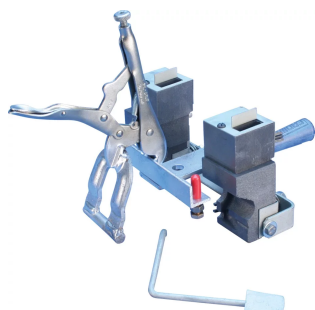

CARACTERISTICI

Complete welder assembly provides a convenient means of attaching jumper bonds to the head of the rail

Connection is made within the confines of the splice plate

Includes mold cleaner and flint ignitor

SPECIFICAȚII

Rail Type: 85 lb to 141 lb T-Rail Sections

Bond Terminal Style: C

Table 1/1

Număr de catalog	Article Number	Material	Conductor Size	Conductor Outer Diameter, Nominal	Bond Length	Welder Style
PBCT8X3		Graphite, Steel, Thermoplastic	50 mm ² Ropelay	9.13mm	177.8mm	T8
PBCT8X6	224422	Graphite, Steel, Thermoplastic	120 mm ² Ropelay	9.53mm	177.8mm	T8
PBCT82S13		Graphite, Steel, Thermoplastic	2/0 Concentric	10.62mm	330.2mm	T8
PBCT82J13		Graphite, Steel, Thermoplastic	2/0 Ropelay	12.19mm	330.2mm	T8
PBCT82J9		Graphite, Steel, Thermoplastic	2/0 Ropelay	12.19mm	228.6mm	T8

Număr de catalog	Article Number	Material	Conductor Size	Conductor OuterDiameter, Nominal	Bond Length	Welder Style
PBCT8S6A13		Graphite, Steel, Thermoplastic	3/0 Composite	14.53mm	330.2mm	T8
PBCT82S9		Graphite, Steel, Thermoplastic	4/0 Ropelay	15.49mm	228.6mm	T8
PBCT8Y5X5		Graphite, Steel, Thermoplastic	95 mm ² Ropelay	15.52mm	177.8mm	T8
PBCT82W13		Graphite, Steel, Thermoplastic	250 kcmil Ropelay	19.05mm	330.2mm	T8

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

⚠ WARNING: This product can expose you to chemicals including diisononyl phthalate, which is known to the State of California to cause cancer. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE