


nVent ERICO Cadweld Exolon, Busbar to Busbar

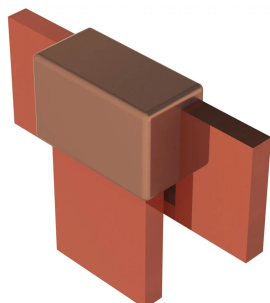

Developed in 1988, nVent ERICO Cadweld Exolon connections represented a significant advancement in welded electrical connections for sensitive indoor applications like data centers, hospitals, and other clean room environments. The virtual elimination of smoke and a unique electronic starting system makes this an ideal solution for sensitive applications. Each nVent ERICO Cadweld Exolon package contains ceramic filters that produce an extremely low emission connection.

CERTIFICATIONS



DIAGRAMS



CARACTERISTICI

Forms a permanent, low resistance connection

Provides a molecular bond

nVent ERICO Cadweld Exothermic Connections are rated with the same current capacity as the conductor

Portable installation equipment with no external source of power required

Installers can be easily trained to make nVent ERICO Cadweld Exothermic Connections

Connections can be visually inspected

SPECIFICAȚII

Table 1/1

Număr de catalog	Mold Family	Lug/Busbar Size 1	Lug/Busbar Size 2	Certifications
------------------	-------------	-------------------	-------------------	----------------

XLBQCCAJCAJ	BQ	3 mm x 25 mm	3 mm x 25 mm	
XLBFDCAJPAM	BF	3 mm x 25 mm	6 mm x 50 mm	
XLBFDCAJPAMS	BF	3 mm x 25 mm	6 mm x 50 mm	
XLBQCCAJPAM	BQ	3 mm x 25 mm	6 mm x 50 mm	
XLBQCCAJPAMS	BQ	3 mm x 25 mm	6 mm x 50 mm	
XLBACCAJ	BA	3 mm x 25 mm	3 mm x 25 mm	UL, cUL

DETALII SUPLIMENTARE DESPRE PRODUS

A gap between conductors may be required. See mold tag for more information.

XL-XX-X-XX-XX-L-M-W		
XL	ERICO CADWELD EXOLON Designation	
XX	Mold Family	
X	Price Key	
XX	Lug/Busbar Size 1	
XX	Lug/Busbar Size 2	
L*	Split Crucible	Crucible section is split on molds designed with horizontal opening for easier cleaning
M*	Mold Only	
W*	Wear Plates	Reduce mechanical abrasion of molds at cable entry points

* Empty if none

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE