

nVent ERICO Ericontact Single Rail Contact



The nVent ERICO Ericontact series of rail contacts provides a superior quality connection to the rail web with a very low contact resistance. The contacts are quickly and easily fitted by means of an insertion tool, regardless of weather conditions. All nVent ERICO Ericontact components are manufactured according to high standards and norms. Tested to the most demanding requirements of the Rail Industry Standards, nVent ERICO Ericontact is the ideal solution for mechanically applied connections such as signal engineering, earthing (grounding), or traction return current.

CARACTERISTICI

Easy to install

Very low contact resistance ($< 5 \mu\Omega$)

Meets AREMA® Recommendations

SPECIFICAȚII

Table 1/2

Număr de catalog	Article Number	Rail Web Thickness	Rail Type	Drill Hole Diameter	Screw Diameter (Sc)	Screw Length (L)
SK13518	715089	14.0 - 18.5 mm	136 lb RE, 141 lb AB	13.5mm	10	55mm
SK1914	715050	14.0 - 16.9 mm	100 lb ARAB, 115 lb AREA, 127 lb NYC, 132 lb RE, 85 lb ASCE, AS50, AS60	19mm	12	55mm
SK1914L		14.0 - 16.9 mm	100 lb ARAB, 115 lb AREA, 127 lb NYC, 132 lb RE, 85 lb ASCE, AS50, AS60	19mm	12	70mm

Număr de catalog	Article Number	Rail Web Thickness	Rail Type	Drill Hole Diameter	Screw Diameter (Sc)	Screw Length (L)
SK1914SS	715051	14.0 - 16.9 mm	100 lb ARAB, 115 lb AREA, 127 lb NYC, 132 lb RE, 85 lb ASCE, AS41, AS50	19mm	12	55mm
SK1912	715045	12.0 - 13.9 mm	AS41, BHP42, BS90A, RI59, RI60, S41	19mm	12	55mm

Table 2/2


Număr de catalog	Article Number	Washer Inner Diameter	Washer Outer Diameter	Nut Material
SK13518	715089	10.5mm	20mm	Electroplated Steel
SK1914	715050	13mm	24mm	Electroplated Steel
SK1914L		13mm	24mm	Electroplated Steel
SK1914SS	715051	13mm	24mm	Stainless Steel 304
SK1912	715045	13mm	24mm	Stainless Steel 304

DETALII SUPLIMENTARE DESPRE PRODUS

Kit includes: (1) hex-head stainless steel 304 bolt, (1) nVent ERICO Ericontact stainless steel 304 SK-washer, (1) electrolytically tin-plated copper bush, (1) stainless steel 304 flat washer, and (1) hexagonal stainless steel 304 nut or (1) electroplated steel nut (depending on contact type).

The washer and nut for SK135165 are integrated into one piece.

DIAGRAMS

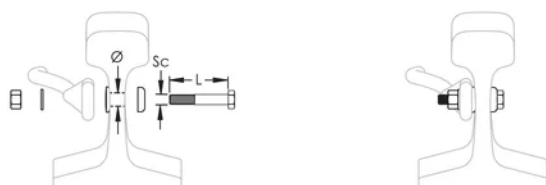

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE