


Stamped Bolted Parallel Cable Connector

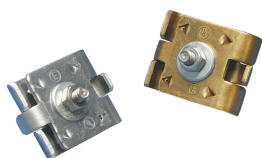

CERTIFICATIONS



CARACTERISTICI

For positive bolt tension cable clamping

Listed to UL® 96

SPECIFICAȚII

Conductor Size, UL: Class 1 - Class 2 (4/0 Max)


Table 1/1

Număr de catalog	Material	Finish	Depth (D)	Height (H)	Width (W)	Unit Weight
LPA502	Aluminiu		38.1mm	38.1 mm	45.2 mm	0.04 kg
LPC502L	Copper	Tinned	38.1mm	38.1 mm	45.2 mm	0.09 kg
LPC502	Copper		38.1mm	38.1 mm	45.2 mm	0.09 kg

DETALII SUPLIMENTARE DESPRE PRODUS

Stainless steel separator included with LPC502A for bi-metallic applications.

DIAGRAMS

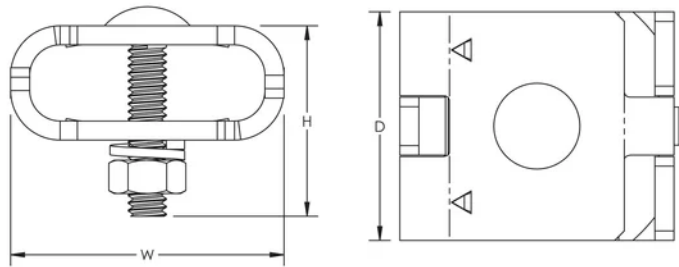

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE