

# Tape Support Clamp, Wall Mount



## CARACTERISTICI

Secures tape conductor to buildings and other structures

## SPECIFICAȚII


Table 1/2

| Număr de catalog | Article Number | Material | Finish              | Tape Size     | Depth (D) | Height (H) |
|------------------|----------------|----------|---------------------|---------------|-----------|------------|
| SSF6C            | 107560         | Copper   | Bare                | 30 x 6 mm Max | 28mm      | 60 mm      |
| SSF6GS           | 107550         | Oțel     | Electro galvaniz ed | 30 x 6 mm Max | 28mm      | 60 mm      |

Table 2/2

| Număr de catalog | Article Number | Width (W) | Hole Size (HS) | X             | Unit Weight |
|------------------|----------------|-----------|----------------|---------------|-------------|
| SSF6C            | 107560         | 36 mm     | 9.5 mm         | 6.5 x 15.5 mm | 0.13 kg     |
| SSF6GS           | 107550         | 36 mm     | 9.5 mm         | 6.5 x 15.5 mm | 0.14 kg     |

DIAGRAMS

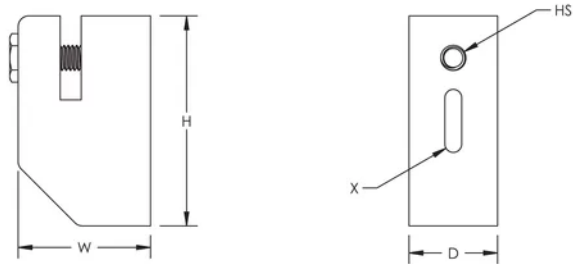

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE