


Telecom Grounding Busbar

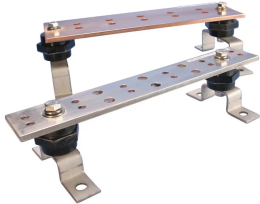

CERTIFICATIONS



CARACTERISTICI

Meets TIA-607-C and TIA-607-D conforms to BICSI® recommendations

Complies with NEMA® standards

Accepts two hole lugs with 5/16" or 7/16" bolt holes (hardware not included)

Telecom grounding busbar splice kits are available to extend the length of the busbar

SPECIFICAȚII

Thickness (T): 6.35 mm

Width (W): 50.8 mm

Material: Copper

Table 1/2


Număr de catalog	Tin Plating	Length 1 (L1)	Length 2 (L2)	Hole Size 1 (HS1)	Hole Size 1 Number of Pairs	Hole Size 2 (HS2)
TGBA12L06P	No	305 mm	229 mm	8 mm	6	11 mm

Număr de catalog	Tin Plating	Length 1 (L1)	Length 2 (L2)	Hole Size 1 (HS1)	Hole Size 1 Number of Pairs	Hole Size 2 (HS2)
TGBA12L06PT	Yes	305 mm	229 mm	8 mm	6	11 mm
TGBA20L12PT	Yes	508 mm	229 mm	8 mm	12	11 mm
TGBA24L14P	No	610 mm	457 mm	8 mm	14	11 mm
TGBA24L14PT	Yes	610 mm	457 mm	8 mm	14	11 mm
TGBA29L18PT	Yes	737 mm	457 mm	8 mm	18	11 mm

Table 2/2

Număr de catalog	Hole Size 2 Number of Pairs	A	B	C
TGBA12L06P	3	25.4 mm	28.6 mm	15.9 mm
TGBA12L06PT	3	25.4 mm	28.6 mm	15.9 mm
TGBA20L12PT	3	25.4 mm	28.6 mm	15.9 mm
TGBA24L14P	5	25.4 mm	28.6 mm	15.9 mm
TGBA24L14PT	5	25.4 mm	28.6 mm	15.9 mm
TGBA29L18PT	5	25.4 mm	28.6 mm	15.9 mm

 DIAGRAMS



AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răni corporale grave și moarte.

și/sau poate anula garanția dvs.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY	ERICO	HOFFMAN	ILSCO	SCHROFF	TRACHTE
-------	-------	---------	-------	---------	---------