

Universal Ground Rod Clamp, Rod to Conductor, Bronze



The nVent ERICO Universal acorn clamp line-up is a cost-effective and reliable way to connect ground rods to conductors throughout your grounding and bonding system. Suitable for both above ground and below grade installation, the clamp tightens the components together with tools that are available on every jobsite.

Now available in the most commonly requested universal size, you can carry less with you on the job and get more done.

When you're choosing your preferred connection method, make sure to reach out to our team with any technical questions or engineering needs.

CERTIFICATIONS



CARACTERISTICI

For use with copper-bonded ground rods

Parts that are UL 467 Listed are suitable for direct burial in earth or concrete

SPECIFICAȚII


Table 1/2

Număr de catalog	Article Number	Material	Ground Rod Diameter, Nominal	Ground Rod Diameter, Actual (Ø)	Conductor Size	Rebar Size, Canada
CP34	158175	Silicon Bronze	1/2" - 3/4"	12.5 - 17.3 mm	#10 Solid - 1/0 Stranded, 6 mm ² Solid - 50 mm ² Stranded	10M

Table 2/2

Număr de catalog	Article Number	Rebar Size, Metric	Rebar Size, US	Wrench Size	Complies With	Torque (TQ)
CP34	158175	12 mm	#4	1/2"	IEC® EN 62561-1	16.9 N·m

DIAGRAMS

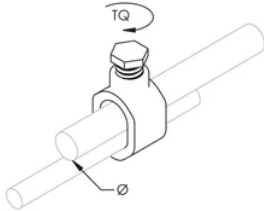

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

⚠ **WARNING:** This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE