


CABS Busbar Support Kit

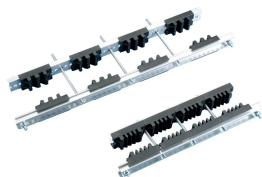

CERTIFICATIONS



CARACTERISTICI

For all busbar types

Improve bending resistance by interlocking or stacking two profiles

Quick and easy to install

Halogen free insulators

RoHS compliant

SPECIFICAȚII

Typical Application Current Rating:	400 - 4500 A
Max Working Voltage, IEC (Ui):	1000;1500
Finish:	Electrogalvanized
Complies With:	IEC® 60439.1;IEC® 61439.1;IEC® 60695-2-11 (Glow Wire Test 960 °C)
Flammability Rating:	UL® 94V-0
Working Temperature:	-40 to 130 °C

Table 1/2


Număr de catalog	Article Number	Material	Busbars per Phase	Busbar Width	Busbar Thickness	Depth (D)
------------------	----------------	----------	-------------------	--------------	------------------	-----------

CABS4-5TN-400	549310	Aluminum, Glass Fibre Reinforced Polyamide, Oțel	1 - 4	30 - 125 mm	5 mm	39mm
CABS4-5TN-600	549260	Aluminum, Glass Fibre Reinforced Polyamide, Oțel	1 - 4	30 - 125 mm	5 mm	39mm
CABS2-10TN-400	549320	Aluminum, Glass Fibre Reinforced Polyamide, Oțel	1 - 2	30 - 120 mm	10 mm	39mm
CABS2-10TN-600	549270	Aluminum, Glass Fibre Reinforced Polyamide, Oțel	1 - 2	30 - 120 mm	10 mm	39mm

Table 2/2

Număr de catalog	Article Number	Width (W)	A	B	C	Unit Weight
CABS4-5TN-400	549310	350 mm	300 mm	75 mm	325 mm	0.8 kg
CABS4-5TN-600	549260	550 mm	500 mm	75 - 125 mm	525 mm	0.84 kg
CABS2-10TN-400	549320	350 mm	300 mm	75 mm	325 mm	0.77 kg
CABS2-10TN-600	549270	550 mm	500 mm	75 - 125 mm	525 mm	0.81 kg

DIAGRAMS

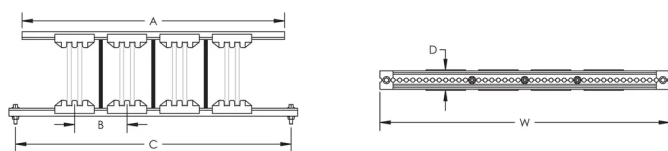

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE