


CABS Module Kit with Neutral

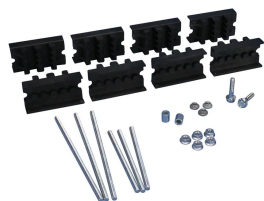

CERTIFICATIONS



CARACTERISTICI

Modules provide flexibility to select distance between phases and supports

Installs quickly and easily

Halogen free insulators

RoHS compliant

SPECIFICAȚII

Typical Application Current Rating:	400 - 4500 A
Max Working Voltage, IEC (Ui):	1000;1500
Finish:	Electrogalvanized
Complies With:	IEC® 60439.1;IEC® 61439.1;IEC® 60695-2-11 (Glow Wire Test 960 °C)
Flammability Rating:	UL® 94V-0
Working Temperature:	-40 to 130 °C

Table 1/2

Număr de catalog	Article Number	Material	Busbars per Phase	Busbar Width	Busbar Thickness	Depth (D)
------------------	----------------	----------	-------------------	--------------	------------------	-----------

CABS4-5TN-MOD	549340	Oțel, Glass Fibre Reinforced Polyamide	1 - 4	30 - 125 mm	5 mm	39mm
CABS2-10TN-MOD	549350	Oțel, Glass Fibre Reinforced Polyamide	1 - 2	30 - 120 mm	10 mm	39mm
CABS3-10TN-MOD	549360	Oțel, Glass Fibre Reinforced Polyamide	1 - 3	30 - 120 mm	10 mm	39mm

Table 2/2

Număr de catalog	Article Number	Width (W)	Unit Weight
CABS4-5TN-MOD	549340	75 mm	0.5 kg
CABS2-10TN-MOD	549350	75 mm	0.48 kg
CABS3-10TN-MOD	549360	100 mm	0.58 kg

DETALII SUPLIMENTARE DESPRE PRODUS

CABS modules must be installed on CABS-APP Aluminium Profile.

DIAGRAMS



AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răni corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE