

DRGN Clip Nut for Asymmetric DIN Rail



CERTIFICATIONS



CARACTERISTICI

Designed to be installed on asymmetric DIN profiles

Provides threaded holes to fix equipment on DIN profile

SPECIFICAȚII

Finish: Electrogalvanized

Table 1/2


Număr de catalog	Article Number	Material	Thread Size 1 (TS1)	Thread Size 2 (TS2)	Width (W)	Height (H)
DRGNM6	558080	Oțel, Polyamide	M4	M6	12 mm	25 mm
DRGNM5	558070	Oțel, Polyamide	M3	M5	12 mm	25 mm

Table 2/2

Număr de catalog	Article Number	Unit Weight
------------------	----------------	-------------

DRGNM6	558080	0.04 kg
DRGNM5	558070	0.04 kg

DIAGRAMS

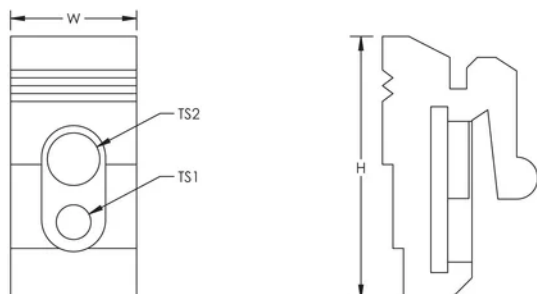

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE