


MFFC nVent ERIFLEX Flexibar Folding Tool Clamp

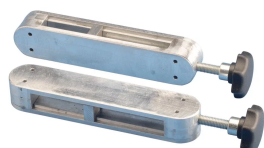

CERTIFICATIONS



CARACTERISTICI

Prevents nVent ERIFLEX Flexibar laminates from sliding during the folding process

Use as a guide when stripping insulation

Intended for use with nVent ERIFLEX Flexibar

SPECIFICAȚII

Material: Oțel

Table 1/1

Număr de catalog	Article Number	Conductor Width	Height	Length	Width	Unit Weight
MFFC63	558934	20 - 63 mm	50 mm	250mm	50 mm	0.45 kg
MFFC120	558935	20 - 120 mm	50 mm	250mm	50 mm	0.54 kg

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE