

nVent ERIFLEX Flexbus Transformer Cover IP2X for 2 Conductors per Phase



CERTIFICATIONS



CARACTERISTICI

Input/output for neutral/ground conductor

Resistance to solvent and hydrocarbon splashes

Installs quickly and easily

UV resistance

SPECIFICAȚII

Table 1/2


Număr de catalog	Article Number	Material	Working Temperature	Length (L)	Width (W)	Depth (D)
FLEXCOVIP2XT WO	508161	Polyvinylchloride	-40 to 140 °C	670mm	230 mm	180mm

Table 2/2

Număr de catalog	Article Number	Unit Weight
------------------	----------------	-------------

FLEXCOVIP2XTWO	508161	0.84 kg
----------------	--------	---------

DIAGRAMS

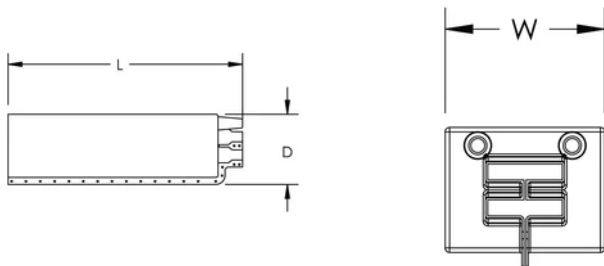

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE