

PDRG Perforated Asymmetric Profile



CERTIFICATIONS



CARACTERISTICI

Rapid assembly of all kinds of frameworks

High mechanical resistance

High corrosion resistance

Conforms to EN 60715 and 50035 and DIN 46277

RoHS compliant

SPECIFICAȚII

Finish: Electrogalvanized

Material: Oțel


Table 1/2

Număr de catalog	Article Number	Height (H)	Width (W)	Length (L)	Thickness (T)	A
PDRG-2M	558050	32 mm	15 mm	2000mm	1.5 mm	9 mm
PDRG-3M	558060	32 mm	15 mm	3000mm	1.5 mm	9 mm

Table 2/2

Număr de catalog	Article Number	B	C	D	Unit Weight
PDRG-2M	558050	7 mm	18 mm	6.2 mm	1.3 kg
PDRG-3M	558060	7 mm	18 mm	6.2 mm	1.96 kg

DIAGRAMS

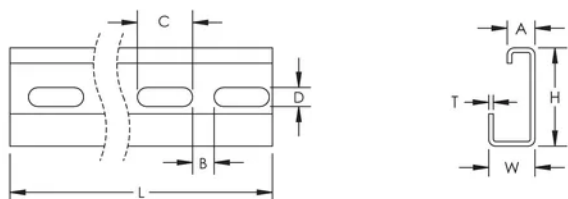

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE