


Universal Busbar Support with Neutral Circuit

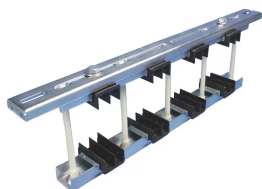

CERTIFICATIONS



CARACTERISTICI

Universal fixing system

Installs quickly and easily

Extremely robust construction

Adjustable arms for easy mounting

Halogen free insulators

SPECIFICAȚII

Max Working Voltage, IEC (Ui):	1000;1500
Complies With:	IEC® 60439.1;IEC® 61439.1;IEC® 60695-2-11 (Glow Wire Test 960 °C)
Flammability Rating:	UL® 94V-0
Working Temperature:	-40 to 130 °C

Table 1/2


Număr de catalog	Article Number	Material	Typical Application Current Rating	Busbars per Phase	Busbar Width	Busbar Thickness
------------------	----------------	----------	---------------------------------------	-------------------	--------------	------------------

UBS1-5TN	551000	Oțel, Glass Fibre Reinforced Polyamide	1700 A	1	30 - 125 mm	5 mm
UBS4-5TN	551010	Oțel, Glass Fibre Reinforced Polyamide	3500 A	1 - 4	30 - 125 mm	5 mm
UBS1-10TN	551060	Oțel, Glass Fibre Reinforced Polyamide	2250 A	1	30 - 120 mm	10 mm
UBS2-10TN	551070	Oțel, Glass Fibre Reinforced Polyamide	3600 A	1 - 2	30 - 120 mm	10 mm
UBS3-10TN	551090	Oțel, Glass Fibre Reinforced Polyamide	4500 A	1 - 3	30 - 120 mm	10 mm

Table 2/2

Număr de catalog	Article Number	Width (W)	A	B	C	D
UBS1-5TN	551000	380 - 610 mm	360 - 590 mm	176 mm	300 mm	70 mm
UBS4-5TN	551010	585 - 895 mm	560 - 865 mm	281 mm	480 mm	110 mm
UBS1-10TN	551060	380 - 610 mm	360 - 590 mm	176 mm	300 mm	70 mm
UBS2-10TN	551070	585 - 895 mm	560 - 865 mm	281 mm	480 mm	110 mm
UBS3-10TN	551090	585 - 895 mm	560 - 865 mm	281 mm	480 mm	110 mm

DIAGRAMS

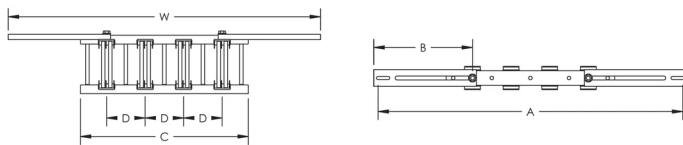

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE