


Barrier Kits Bracket-Mounted

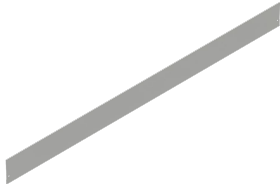

Divides wireway into two or three compartments. Plated spring steel brackets hold barriers in place by friction fit inside wireway. Order barrier and bracket separately. Recommended spacing increments of 3 ft.

CARACTERISTICI

Divides wireway into two or three compartments

Plated spring steel brackets hold barriers in place by friction fit inside wireway

Order barrier and bracket separately. Recommended spacing increments of 3 feet

SPECIFICAȚII

Color Code:	ANSI 61
Finish:	Galvanizat; Vopsit Pulbere
Color:	Gray
Material:	Oțel Zincat

Table 1/1

Număr de catalog	Type	Height	Width	Depth	Thickness	Quick Ship
F44BB2C	Barrier Kit	102mm	102mm	25mm	1.9mm	No
F66BB2C	Barrier Kit	152mm	152mm	25mm	1.9mm	No
F44BB3C	Barrier Kit	102mm	102mm		1.9mm	No
F44B360	Barrier Kit	102mm	102mm	1524mm	1.9mm	No
F66B560	Barrier Kit	152mm	152mm	3048mm	1.9mm	No
F66BB3C	Barrier Kit	152mm	152mm		1.9mm	No

DETALII SUPLIMENTARE DESPRE PRODUS

Sealing Plates package consists of five barriers or five brackets. Each barrier is 60 inches long.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE