


Compact busbar support | Putere și distribuție, ECBS

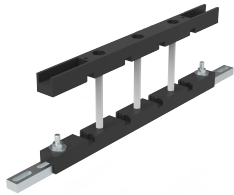

This busbar support, ECBS, is available for one or two bars up to 80 x 5 mm or one bar up to 80 x 10 mm. The support can be mounted both horizontally and vertically. It is available off the shelf and tested according to IEC 61439.

CARACTERISTICI

Descriere: Busbar support up to 1600A to be mounted horizontally or vertically. Mounts directly to the enclosure frame or with help of CLPF profiles. Available in single and double bar per phase for bar thickness 5 mm and only single bar per phase for bar thickness 10 mm, and width from 25 to 80 mm.

Temperatura de lucru: -40°C up to 130°C.

Material: Reinforced polyamide and steel. Halogen free.

Livrare: Busbar support with mounting material.

SPECIFICAȚII

Table 1/1						
Număr de catalog	Enclosure Material	Product Family	Material	Finish	Color	Quick Ship
ECBS110TN	Oțel Zincat	Free-Standing	Polyamide, Oțel	Smooth Matte	Black	No
ECBS205TN	Oțel Zincat	Free-Standing	Plastic, Oțel Zincat	Smooth		No

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE