


Cutoff Fitting Lay-In Hinged Cover

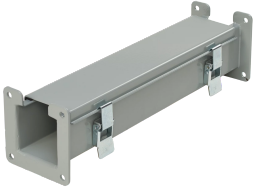

Lay-In Hinged Cover Cutoff Fittings are used for lengths of 9.00 inch (229 mm) to 15.00 inch (381 mm). Body comes in two pieces. Shorten body and cover to the desired length and weld together. Fittings are finished with paint over plated surfaces.

CARACTERISTICI

Lay-In Hinged Cover Cutoff Fittings are used for lengths of 9.00 inch (229 mm) to 15.00 inch (381 mm)

Body comes in two pieces. Shorten body and cover to the desired length and weld together

Fittings are finished with paint over plated surfaces

SPECIFICAȚII

- Color Code:** ANSI 61
- Finish:** Galvanizat; Vopsit Pulbere
- Color:** Gray
- Material:** Oțel Zincat

Table 1/1						
Număr de catalog	Type	Height	Width	Thickness	Sealing Plate Type	Sealing Plate Quantity
F126LXL	Cut-Off Fitting	305mm	152mm	1.9mm	Flat	1
F22LXL	Cut-Off Fitting	64mm	64mm	1.9mm	Flat	1
F88LXL	Cut-Off Fitting	203mm	203mm	1.9mm	Flat	1
F66LXL	Cut-Off Fitting	152mm	152mm	1.9mm	Flat	1
F44LXL	Cut-Off Fitting	102mm	102mm	1.9mm	Flat	1

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE