

PFF Parallel Plastic Screw-In Plug for P13/P14 Couplers, European Design



The European Design Version (Suffix EE) is currently being phased out. All future projects should be designed with the Worldwide Design Version (Suffixes N and LN). This change is being done in order to simplify our product offering and eliminate redundant designs. Please contact Customer Care or your local Sales Engineer/Manager if you require more information on this transition.

CARACTERISTICI

Designed for use with the P13/P14 coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Durable mounting plates allow for easy attachment to forms

Color coded for the appropriate coupler size

SPECIFICAȚII

Design Version: European (Specialty Materials)

Table 1/2


Număr de catalog	Article Number	Material	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)
EL1416PFF	153810	High Density Polyethylene (HDPE), Oțel	14 mm, 16 mm	#5	15M	65 mm
EL1012PFF	153800	High Density Polyethylene (HDPE), Oțel	10 mm, 12 mm	#3, #4	10M	65 mm
EL2225PFF	153840	High Density Polyethylene (HDPE), Oțel	22 mm, 25 mm	#7, #8	25M	95 mm

Număr de catalog	Article Number	Material	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)
EL2830PFF	153850	High Density Polyethylene (HDPE), Oțel	28 mm, 30 mm	#9	30M	95 mm
EL20PFF	153830	High Density Polyethylene (HDPE), Oțel	20 mm	#6	20M	75 mm
EL18PFF	153820	High Density Polyethylene (HDPE), Oțel	18 mm			75 mm
EL32PFF	153860	High Density Polyethylene (HDPE), Oțel	32 mm	#10		95 mm
EL40PFF	153870	High Density Polyethylene (HDPE), Oțel	40 mm			95 mm

Table 2/2

Număr de catalog	Article Number	Height (H)	Color
EL1416PFF	153810	15 mm	Black
EL1012PFF	153800	15 mm	Red
EL2225PFF	153840	18 mm	Red
EL2830PFF	153850	18 mm	Black
EL20PFF	153830	18 mm	Yellow
EL18PFF	153820	18 mm	White
EL32PFF	153860	18 mm	Yellow
EL40PFF	153870	18 mm	Green

DIAGRAMS

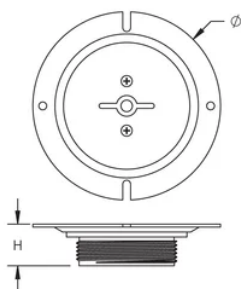

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE