

T-Series Vertical Transition Filler Material Kit



T-Series vertical filler material kits contain the following: Filler material, two vertical packings, pouring basin ceramic guide tube and pouring basin crucible ceramic and disk. All filler material kits contain one-time use components that are sized to a specific sleeve, pouring basin and pouring basin crucible combination. Ordering filler material kits simplifies ordering, reduces order errors and helps ensure proper sizing of components.

CARACTERISTICI

Simplifies ordering

Used to splice different diameter bars

All components are for one-time use

SPECIFICAȚII

Table 1/1

Număr de catalog	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada
RBT911101B	36 mm, 28 mm	#11, #9	35M, 30M
RBT910101B	32 mm, 28 mm	#10, #9	
RBT1114101B	43 mm, 36 mm	#14, #11	45M, 35M
RBT1118101B	57 mm, 36 mm	#18, #11	55M, 35M
RBT1011101B	36 mm, 32 mm	#11, #10	
RBT1418101B	57 mm, 43 mm	#18, #14	55M, 45M

DETALII SUPLIMENTARE DESPRE PRODUS


Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System instruction manual.

Filler material kits are a component in splice kits. Care should be taken to avoid duplication of orders.

Components can also be purchased separately: (1) Filler Material, (2) Vertical Top Packing, (3) Vertical Bottom Packing, (4) Pouring Basin Ceramic Guide Tube, and (5) Crucible Ceramic and Disk.

Filler Material Kit Components				
Filler Material Kit	Filler Material	Packing (2 Required)	Pouring Basin Ceramic Insert and Disk	Pouring Basin Ceramic Guide Tube
RBT910101B	RBF105	RBS354712 RBS35475.5	RBS5037	RBS5038
RBT911101B	RBF125	RBS354714 RBS35476	RBS5037	RBS5038
RBT1011101B	RBF125	RBS354712 RBS35476	RBS5037	RBS5038
RBT1114101B	RBF125	RBS354715 RBS35476	RBS5037	RBS5039
RBT1118101B	RBF240	RBS354712 RBS354720	RBS5037	RBS5039
RBT1418101B	RBF195	RBS354720 RBS35477	RBS5037	RBS5039

DIAGRAMS

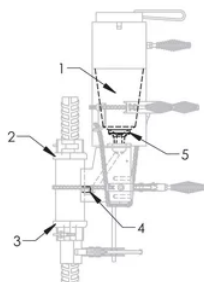

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE