


EuropacPRO 19" Subrack Kit for Backplane, Light, Unshielded

Power Utilities

Non-EMC shielded subrack for backplane mounting, light version.

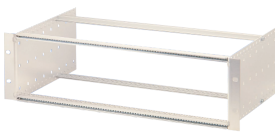

CERTIFICATIONS



CARACTERISTICI

Subrack with side panel type L ("light") with integrated 19" support brackets

Horizontal rail type "light"

Aluminum construction

Rear horizontal rails for backplane mounting with insulation strip

Installed load up to 7.5 kg

Supplied as space-saving flat-pack

Internal and external dimensions in accordance with: IEC 60297-3-100, -101, IEEE 1101.1

Modifications such as cutouts, different finishes or dimensions available

SPECIFICAȚII

Table 1/2

Număr de catalog	Rack Height	Depth	Package Quantity	For Mounting	Board Depth	Handle Included
24564-433	6 U	295 mm	1	Backplane	160 mm, 220 mm, 280 mm	No
24564-432	6 U	235 mm	1	Backplane	160 mm, 220 mm	No
24564-431	6 U	175 mm	1	Backplane	160 mm	No
24564-133	3 U	295 mm	1	Backplane	160 mm, 220 mm, 280 mm	No
24564-132	3 U	235 mm	1	Backplane	160 mm, 220 mm	No
24564-131	3 U	175 mm	1	Backplane	160 mm	No

Table 2/2

Număr de catalog	Mounting	Complies With	EMC Shielding	Product Type	Rack Width	Static Load
24564-433	Rack	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	No	Subrack/Chassis	84 HP	7.5 kgf
24564-432	Rack	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	No	Subrack/Chassis	84 HP	7.5 kgf
24564-431	Rack	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	No	Subrack/Chassis	84 HP	7.5 kgf
24564-133	Rack	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	No	Subrack/Chassis	84 HP	7.5 kgf
24564-132	Rack	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	No	Subrack/Chassis	84 HP	7.5 kgf
24564-131	Rack	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	No	Subrack/Chassis	84 HP	7.5 kgf

DETALII SUPLIMENTARE DESPRE PRODUS

Subrack is not prepared for shielding, retrofit for protection class IP 20 possible

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE