


Outdoor Unibody HEX

Power Utilities

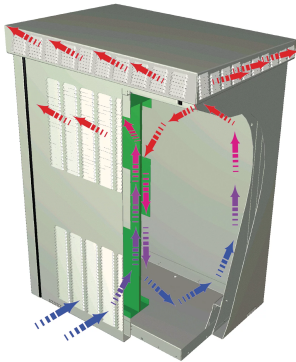

Telecom and Railway applications require sophisticated electronics in outdoor setups. nVent SCHROFF Outdoor cabinets shield such electronic components from extreme weather and vandalism, ensuring operational continuity.

CERTIFICATIONS



CARACTERISTICI

Double-walled, Al

Forced heat dissipation via integrated heat exchanger in the door, max. 70 W/K

IP 55

One-piece inner case with removable outer cladding

SPECIFICAȚII

Table 1/2

Număr de catalog	Product Type	Product Family	Rack Height	Height	Width	Depth
11249-016	Outdoor Cabinet	Unibody	25 U	1330 mm	700 mm	500 mm

Table 2/2

Număr de catalog	Wall Type	Door Type	Access	Cooling	EMC Shielding	Complies With
11249-016	Double Walled	Single Door	Front	Air-to-Air Heat Exchanger	No	IEC 61969-1, IEC 61969-2, IEC 60917-1, IEC 60917-2, ETS 300119, IEC 60529, DIN EN 50178, VDE 0160

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE