

PVT2 Photovoltaic Surge Protection Class II

Power Utilities



CERTIFICATIONS



CARACTERISTICI

Suited for use at the DC input of distributed string inverters in solar arrays

Thermal protection included to ensure safe failure modes


Compact, yet high surge rated pluggable design, using minimum DIN rail width

SPECIFICAȚII

Număr de catalog	PVT21000R	PVT21500R
Max Continuous Operating Voltage (Ucpv)	1,100 V	1,500 VDC
Nominal Discharge Current (In), IEC	20 kA 8/20 μs	20 kA 8/20 μs
Max Discharge Current (Imax)	40 kA 8/20 μs	30 kA 8/20 μs
Total Discharge Current (Itotal)	50 kA 8/20 μs	40 kA 8/20 μs
Voltage Protection Level (Up)	4,000 V	5,000 V

Număr de catalog	PVT21000R	PVT21500R
Response Time	25 ns Max	25 ns Max
Short Circuit Current Rating (Isccr)	11 kA	11 kA
Max Continuous Operating Voltage (VpvdC)	1,100 VDC	1,500 VDC
Voltage Protection Rating (VPR)	2,500 V	4,000 V
Nominal Discharge Current (In), UL	20 kA 8/20 μs	20 kA 8/20 μs
Short Circuit Current Rating (SCCR)	50 kA	65 kA
Protection Modes	-ve to PE -ve to +ve +ve to PE	-ve to PE -ve to +ve +ve to PE
Altitude	2,000 m Max	2,000 m Max
Humidity	5 – 95 % RH	5 – 95 % RH
Temperature	-40 to 85 °C	-40 to 85 °C
Connection, Flexible	25 mm ²	25 mm ²
Connection, Solid	35 mm ²	35 mm ²
Connection, Stranded	35 mm ²	35 mm ²
Enclosure Rating	IP 20	IP 20
Remote Contact Switching Capacity	1.0 A @ 125 VAC 1.0 A @ 250 VAC 0.5 A @ 12 VDC 0.5 A @ 24 VDC 0.5 A @ 48 VDC	1.0 A @ 125 VAC 1.0 A @ 250 VAC 0.5 A @ 12 VDC 0.5 A @ 24 VDC 0.5 A @ 48 VDC
Remote Contacts	Yes	Yes
Status Indication	Mechanical flag	Mechanical flag
Height (H)	90 mm	90 mm
Width (W)	54 mm	54 mm
Unit Weight	0.410 kg	0.450 kg
Replacement Module	PVT2500M	PVT2750M
Certification Details	UL® 1449 Edition 5 Type 1CA	UL® 1449 Edition 5 Type 1CA

DIAGRAMS

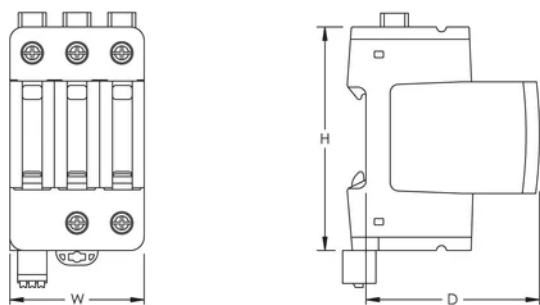

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE