

Rebar Grounding Clamp, Parallel

Power Utilities



CERTIFICATIONS



CARACTERISTICI

Universal use for rebar, rods or pipes

Lay-in feature cuts installation time


Bronze alloy construction with Stainless Steel 304 screws

Approved for direct burial in earth and concrete

SPECIFICAȚII

Table 1/1

Număr de catalog	Article Number	Ground Rod Diameter, Actual (Ø)	Water Pipe Size (Ø)	Rebar Size, Metric
EK16	710355	12.7 – 25.4 mm	12.7 – 25.4 mm	12 – 25 mm

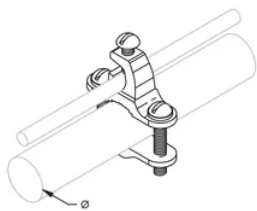

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

⚠ **WARNING:** This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE