


19" Front Panel for Cable Eyes

19" front panel are for accommodating cable eyes.

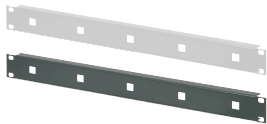

CERTIFICATIONS



CARACTERISTICI

19" front panel to accommodate cable eyes (to mount the eyes, insert and rotate them 45°)

SPECIFICAȚII

Depth:	1.5mm
Rack Width:	95HP
Accessory Type:	Front panel
Product Type:	Front Panel
Material:	Oțel

Table 1/2

Număr de catalog	Rack Height	Mounting	Package Quantity	Front Finish	Rear Finish	Color Code
20118-761	1U	Screw-on Front	1	Painted	Painted	RAL 7035
20118-762	1U	Screw-on Front	1	Painted	Painted	RAL 7021

Table 2/2

Număr de catalog	EMC Shielding	Finish	Height	Type	Width	Quick Ship
20118-761	No	Vopsit Pulbere	43.6mm	19" Front Panel	483mm	No
20118-762	No	Vopsit Pulbere	43.6mm	19" Front Panel	483mm	No

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE